

# ABS 3819 18 G

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol:** ABS 3819 18 G

**Product nbr:** 5880371

**Description:** Enclosure. ABS


**Remarks:** Opaque cover



**Including:** Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

**EAN:** 64 18074039057

**El. number:**

- Finland: 3423761
- Denmark:
- Sweden: 2539715

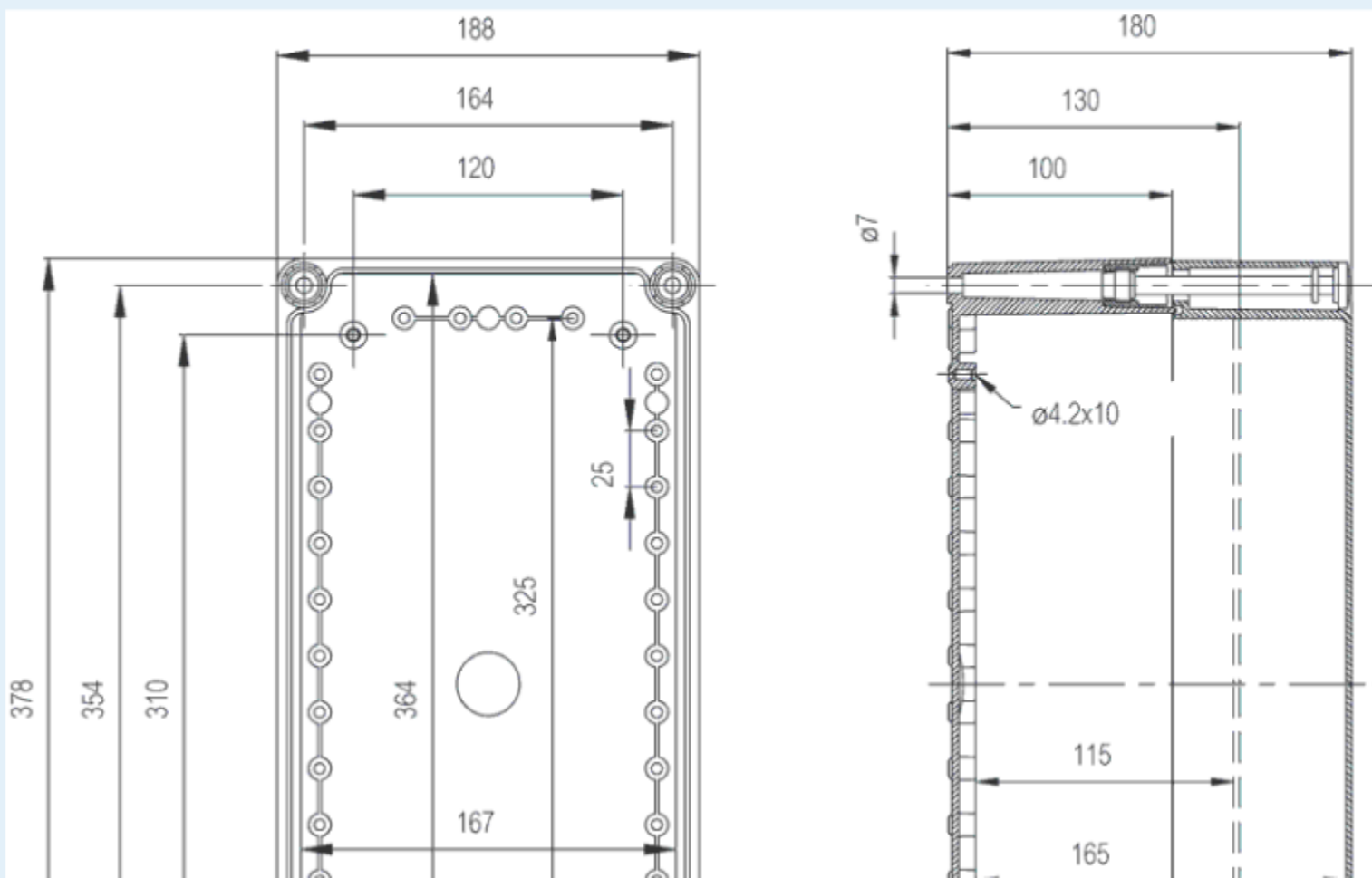

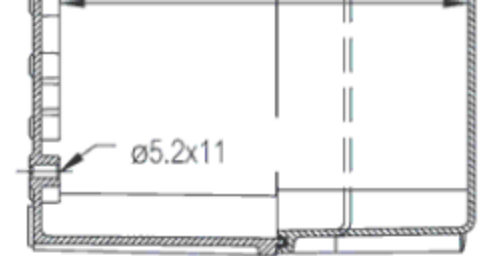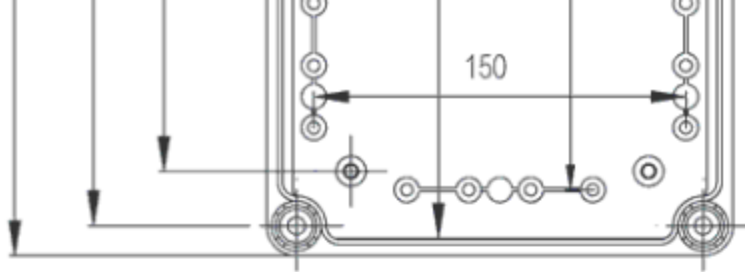

Dimensions:	Height	Width	Depth
mm:	380	190	180
inch:			

#### Materials:

Material:	ABS
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

#### Temperatures:

Temperature °C (short term):	-40 ... 80
Temperature °C (continuous):	-40 ... 60
Temperature °F (short term):	-40 ... 175
Temperature °F (continuous):	-40 ... 140

#### Accessories:

EKMZR	Extension frame. for enclosures: (380 x 190 x 50)
EKV 12	DIN-35 Mounting rail. for enclosures: (160 x 35 x 1)
EKV 32	DIN-35 Mounting rail. for enclosures: (335 x 35 x 1)
EKMVT	Back Panel. for enclosures: (338 x 148 x 1)

#### Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	-
Flammability Rating:	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C:	650 °C
NEMA Class	

#### Certificates:

Certificate NCS FI 30308
--------------------------