

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **2180570205**  
**Status:** **Active**  
**Overview:** EXTreme Guardian System  
**Description:** EXTreme Guardian Female-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, Bluntcut Wires, 11.00mm Pitch, Single Row, 500.00mm Length, 2 Circuits, Black

**Documents:**

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<u>218057</u>
Application	Power, Wire-to-Board
Assembly Configuration	Single Ended Connector
Connector to Connector	EXTreme Guardian-to-Pigtail
Overview	<u>EXTreme Guardian System</u>
Product Name	EXTreme Guardian
Type	Discrete Wire Assembly
UPC	195842766549


**Physical**

Cable Length	500.00mm
Circuits (Loaded)	2
Color - Resin	Black
Gender	Female-Pigtail
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	PBT
Net Weight	210.000/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	11.00mm
Plating min - Mating	0.762µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Size AWG	6
Wire/Cable Type	UL 10669

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	2180570205-000
---------------	----------------

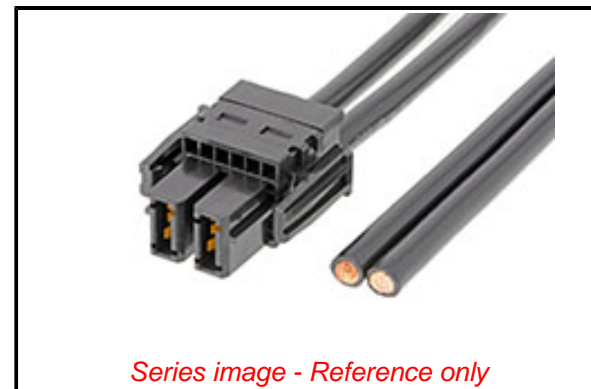

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)10043-DC (17  
Jan 2022)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

218057 Series

**Mates With**

151035 EXTreme Guardian Power Right-Angle PCB Header, 151053 EXTreme Guardian Power Vertical PCB Header