


OStream Wirefree Object Camera

Dimensions

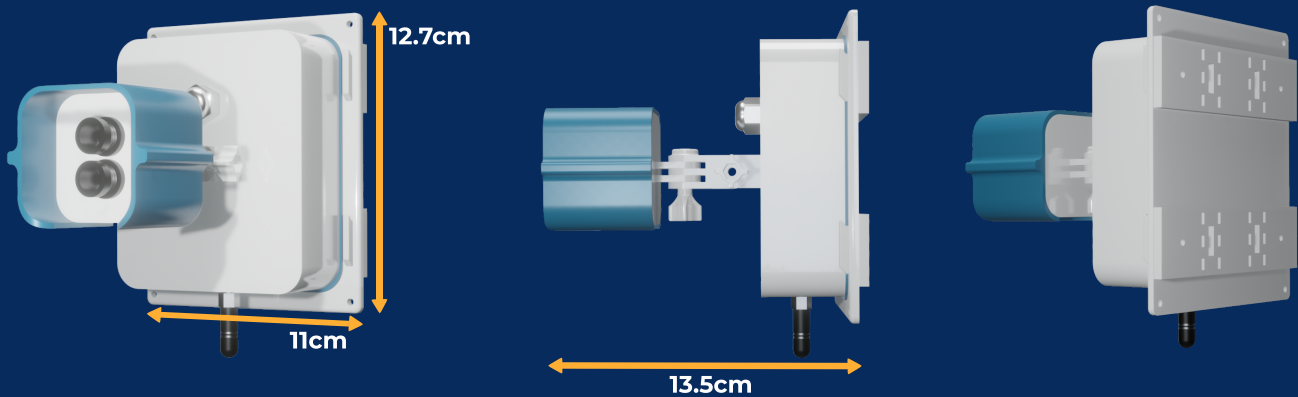

Specifications

Power:	20,000 mAh
Resolutions:	5MP QVGA 320x240 up to QSXGA 2592x1944
Motion Detect:	Computer vision crops objects of interest
Frames Per Sec:	Up to 30; Per resolution and cropped objects
Image Format:	Jpeg
Shutter:	Rolling shutter / frame exposure
Optical Size:	1/4"
Networking:	<ul style="list-style-type: none">- Point to Point Wireless Radios (RipI)- Spectrum: 2.4Ghz Spread Spectrum- Distance: Up to 1KM- Max Bandwidth: 2Mbps
Enclosure:	IP67
Dimensions:	w: 11cm h: 12.7cm d: 13.5cm
Weight:	400g
Certifications:	FCC & CE
CPU:	STM32
Updates:	OTA Through LDAP