

PC 5638 18 G



Sample image

Order symbol: PC 5638 18 G

Product nbr: 5330365

UL Code: 5320365

UL Name: UL PC 5638 18 G

Description: Enclosure. PC

Remarks: Opaque cover


Including: Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

EAN: 6418074005625

El. number:

- Finland: 3423723
- Denmark:
- Sweden: 2539428

SOLID 558x378x180

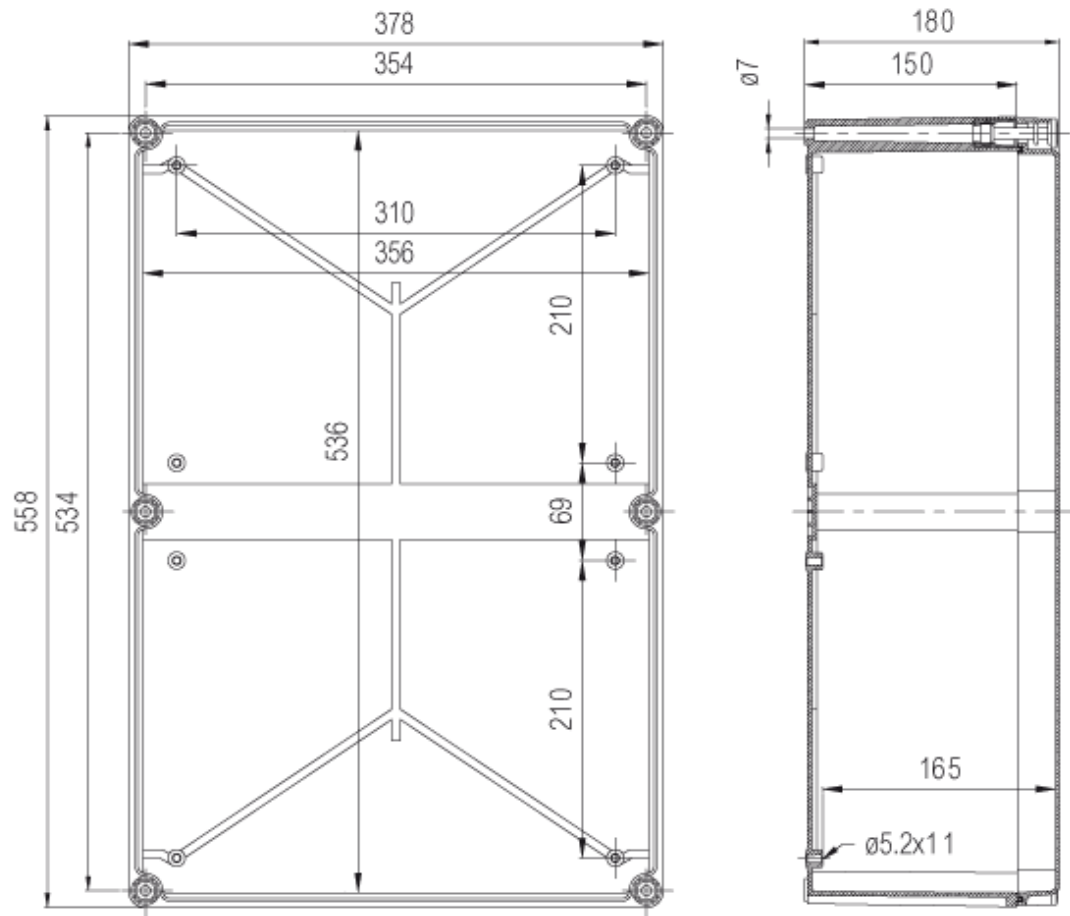

Dimensions:

	Height	Width	Depth
mm:	560	380	180
inch:	22.05	14.96	7.09

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

EKUVT	Back Panel. for enclosures: (518 x 338 x 1)
EKV 32	DIN-35 Mounting rail. for enclosures: (335 x 35 x 1)
EKUZR	Extension frame. for enclosures: (560 x 380 x 50)

Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

Certificate NCS FI 30308