

# L 12 II



Sample image

**Order symbol:** L 12 II

**Product nbr:** 3730775

**Description:** Window for 12 modules


**Remarks:** Smoked transparent cover

**EAN:** 6418074036841

**Including:**

**El. number:**

- Finland: 3422652
- Denmark:
- Sweden: 2539787

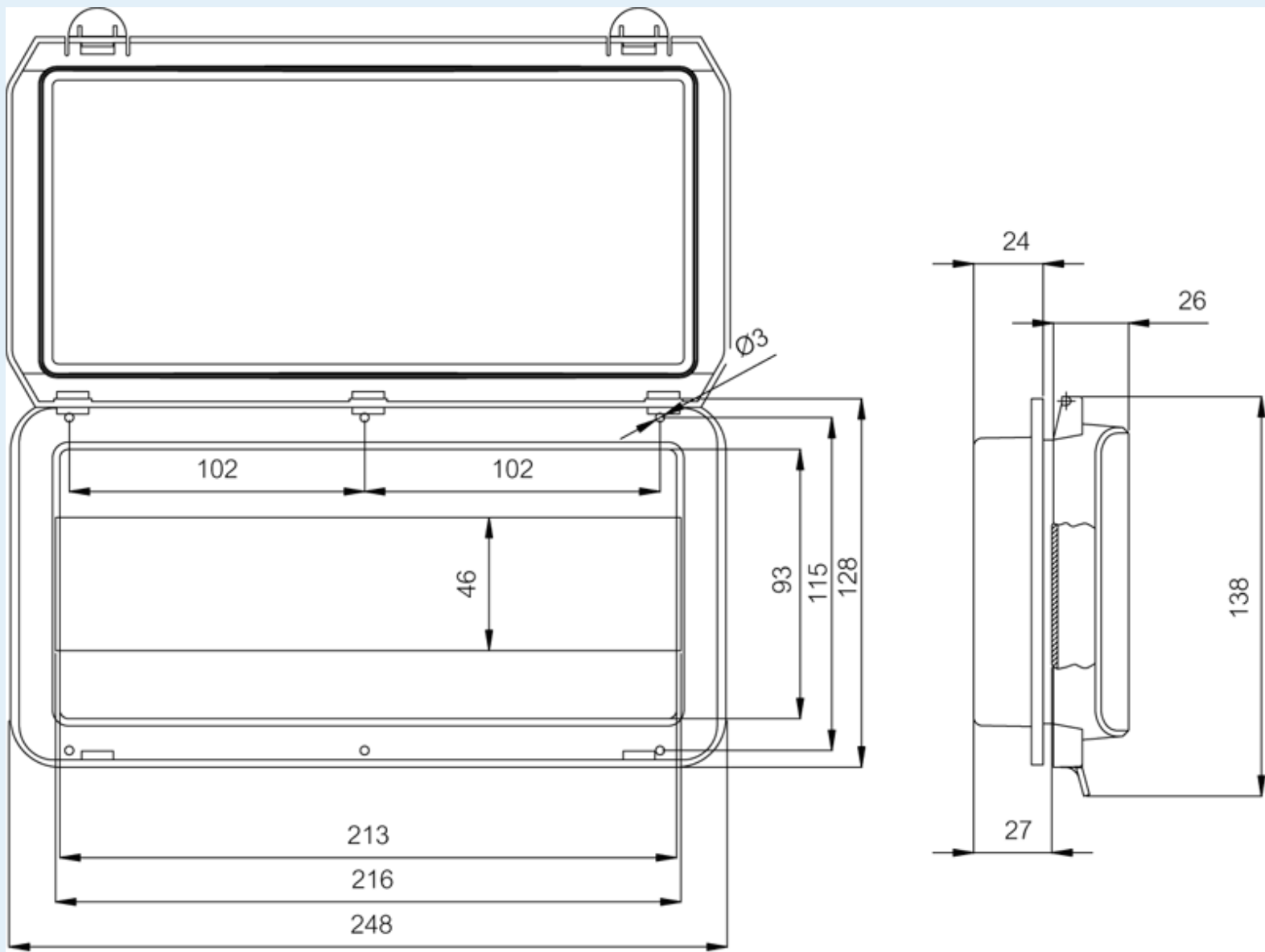

#### Dimensions:

	Height	Width	Depth
mm:	248	128	0
inch:	9.76	5.04	0

#### Materials:

Material:

Base colour:

Cover colour:

Gasket material:

#### Rating:

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	
Electrical insulation:	Not insulated
Halogen free (DIN/VDE 0472, Part 815):	0
UV resistance:	-
Flammability Rating:	
Glow Wire Test (IEC 695-2-1) °C:	C
NEMA Class	

#### Temperatures:

Temperature °C (short term)::	-40 ... 120 °C
Temperature °C (continuous):	
Temperature °F (short term):	-40 ... 250 °F
Temperature °F (continuous):	-40 ... 175 °F

#### Certificates:

