

# PCT 122410



Sample image

**Order symbol:** PCT 122410

**Product nbr:** 7022781

**Description:** Enclosure. PC


**Remarks:** Clear transparent cover

**Including:** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

**EAN:** 6418074058645

**El. number:**

- Finland: 3435408
- Denmark: 8212002911
- Sweden:

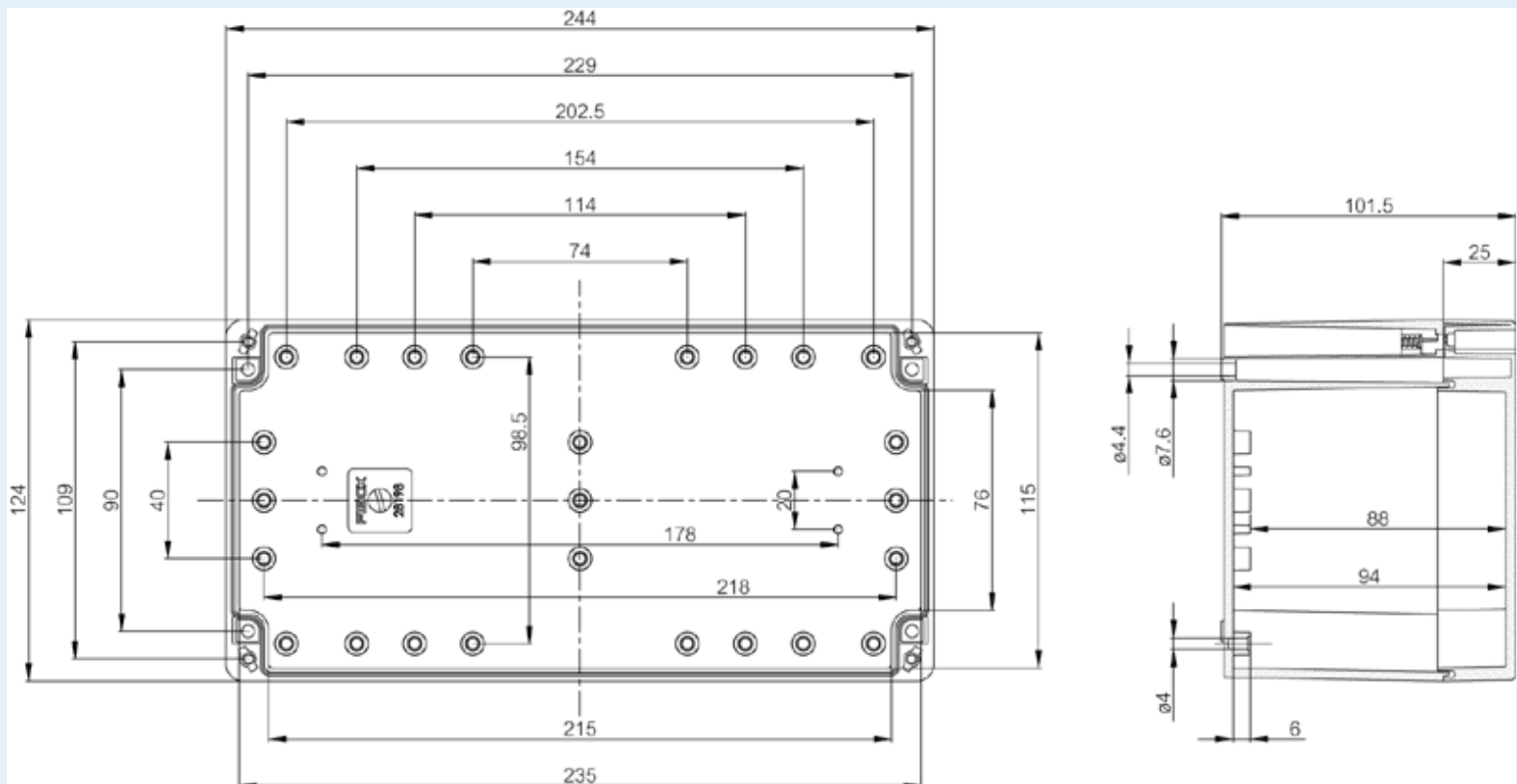

<b>Dimensions:</b>	<b>Height</b>	<b>Width</b>	<b>Depth</b>
mm:	124	244	102
inch:	4.88	9.61	4.02

#### **Materials:**

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	Clear transparent
Gasket material:	Polyurethane

#### **Temperatures:**

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

#### **Accessories:**

TRH 1212	DIN-15 Mounting rail. for enclosures: (110 x 35 x 1)
TRH 24	DIN-15 Mounting rail. for enclosures: (226 x 35 x 1)
TRM 0812	DIN-15 Mounting rail. for enclosures: (106 x 15 x 1)
TF 28037	Mounting foot kit (4 pcs). for enclosures:
MIN 20	DIN-15 Mounting rail. for enclosures: (225 x 15 x 1)
TH A	Gray plastic hinges (2 pcs)
TM 1224	Back Panel. for enclosures:

#### **Rating:**

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

#### **Certificates:**

SGSFimko\_EURONORD