

# LED DRIVER 24VDC 100 WATT IP67-B

## POWERPAX: LED-DR-24V-100W-IP67-B

### Features:

- Input Voltage 200-277Vac
- IP67 Rated
- Class II
- Compact Plastic Low Profile enclosure
- 3 Year Warranty



### Description:

The Range of 100 Watt Constant Voltage LED Drivers are housed in a compact light weight high quality IP67 plastic enclosure with covered input & output terminals suitable for general Indoor LED applications

Specification	
Part Number	LED-DR-24V-100W-IP67-B
Output Voltage	24V±5%
Output Current Range	0-4.17A
Input Power	<120W
Dimensions	212 x 46 x 38.3mm
Input Voltage Range	AC200-277V
Input Voltage Frequency	50-60Hz
Inrush Current	<75A
Efficiency	≥ 85%
Power Consumption Without Load	PF≥0.9
Overload Protection	Ta 0.94-1.06 times of input voltage, 1.2 times of rated power
Short Circuit Protection	Ta 0.94-1.06 times of input voltage
Automatically Restart	Yes
Working Temperature	-40°C to 60°C
Relative Humidity	45% to 85%
MTBF	30,000 Hours.
EMI emission	EN55015
EMC Immunity	EN61000-4-2,3,4,5,6; EN61547
Safety Standards	IEC61347-1, IEC61347-2-13

## POWERPAX


### General Note

TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

# LED DRIVER 24VDC 100 WATT IP67-B

POWERPAX: LED-DR-24V-100W-IP67-B

## Diagrams

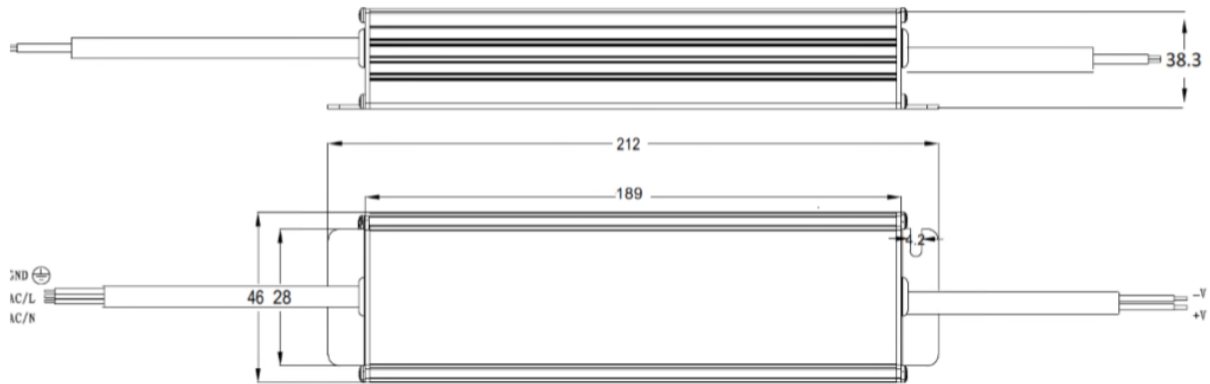

## Wiring Diagram



### General Note

TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.