


CONSTANT VOLTAGE LED DRIVER

12VDC 75WATT

POWERPAX: LED-DR-12V-75W

Features:

- Input Voltage 200-240 Vac
- IP20 Rated
- Low Profile
- Compact Plastic Low Profile enclosure
- 1 Year Warranty

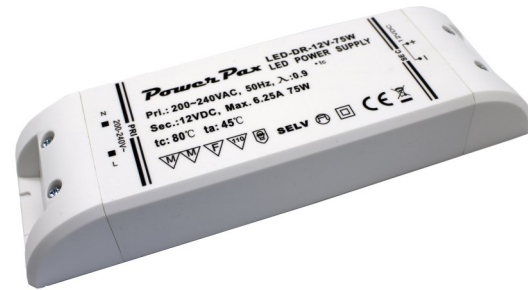

Description:

The Range of 75 Watt Constant Voltage LED Drivers are housed in a compact light weight high quality IP20 plastic enclosure with covered input & output terminals suitable for general Indoor LED applications.

Specification	
Part Number	LED-DR-12V-75W
Output Voltage Rating	12 Vdc
Output Current Range	6.25A
Power Factor	>0.9
Dimensions	200.8(L) x 63.3(W) x 30.3(H) mm
Input Voltage Range	200-240VAC
Input Frequency	50Hz
Efficiency	>85%
Power Consumption Without Load	<0.5W
Overload Protection	Auto Recovery
Short Circuit Protection	Auto Recovery
Over Temperature	Auto Recovery
Operating Temperature	-20°C to +45°C
Ambient Temperature Ta	45°C max
Case Temperature Tc	80°C max
Comparative Humidity	45% to 85%
MTBF	30000hrs
EMI According	EN55015
EMS According	EN61000-3-2; EN61000-3-3; EN61547
Safety Standards	EN61347-1, EN61347-2-13

POWERPAX

General Note


TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

TT Electronics IoT Solutions Ltd
Tofts Farm East, Brenda Road, Hartlepool, TS25 2BQ, UK
t: +44 (0) 1429 852 500

CONSTANT VOLTAGE LED DRIVER 12VDC 75WATT

POWERPAX: LED-DR-12V-75W

Diagrams

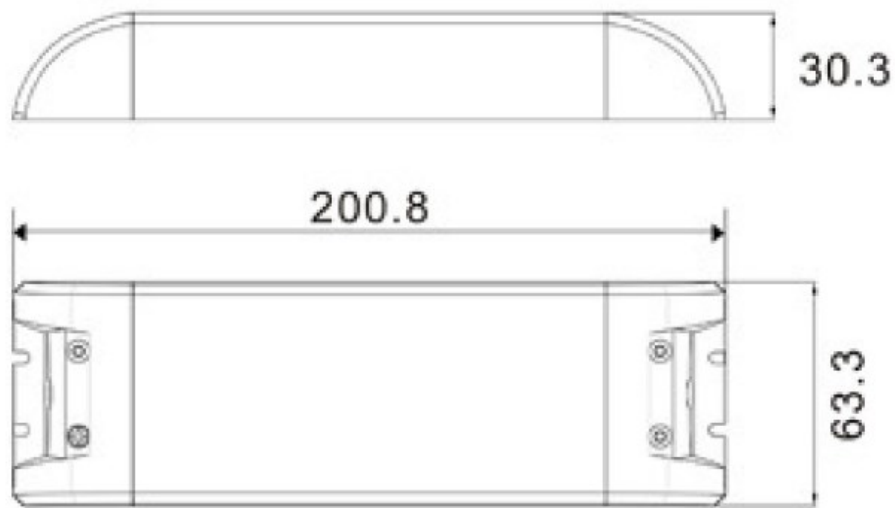

General Note

TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

POWERPAX