

## Product information

# 12 42 195

## KNIPEX MultiStrip 10 Automatic Insulation Stripper



- Stripping without re-adjustment from 0.03 to 10.0 mm<sup>2</sup>
- Recessed wire cutter
- Universal blade geometry – robust and more durable
- Ideal grip design with excellent haptics
- Fully automatic adjustment to fine-stranded conductors with standard insulation throughout the entire capacity range from 0.03 to 10.0 mm<sup>2</sup>
- With recessed wire cutter for Cu and Al conductors, stranded up to 10 mm<sup>2</sup> and single wire up to 6 mm<sup>2</sup>
- No damage to the conductors
- The clamping jaws made of steel hold the cable in a way that prevents slipping without damaging the remaining insulation
- Particularly smooth-running mechanics and very low weight
- Replaceable blades block and length stop
- Handle with soft-plastic zone for a steady grip
- Body: plastic, fibreglass-reinforced
- Blade: special tool steel, oil-hardened

AAA



### General

Article No.	12 42 195
EAN	4003773054580
Weight	136 g
Dimensions	195 x 112 x 18 mm
Reach	yes
RohS	no

### Technical details

Stripping capacities in square millimetres	0.03 — 10.0 mm <sup>2</sup>
AWG	32 — 8


### Classification

eCl@ss 5.1.4	21040302
ETIM 5.0	EC000163
ETIM 6.0	EC000163
proficl@ss 6.0	AAA002c003
UNSPSC 13.1	27111510

### Spare Parts

12 49 04	Torsion spring for 12 40/50 200,
12 49 05	Coil spring in the head for 12 40/50 200,
12 49 21	Spare blades block for 12 42 195,
12 49 22	Spare clamping jaws for 12 42 195,
12 49 23	Spare length stop for 12 42 / 52 195,

technical change and errors excepted

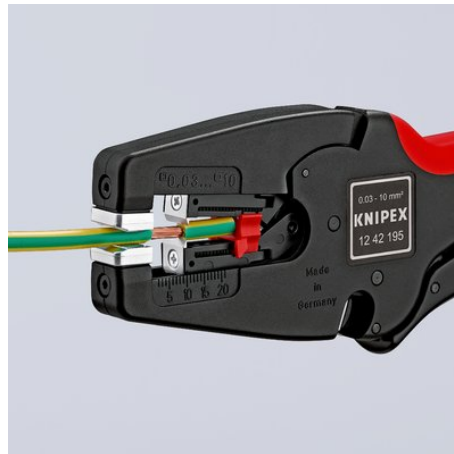

Wire cutter for multiple stranded wire cables up to 10.0 mm<sup>2</sup>