

## Product information

# 13 05 160

## Electricians' Pliers




- The ideal pliers for cable work
- For gripping and bending wire
- For cutting medium hard and hard wire
- Precision cutting edges additionally induction-hardened, cutting edge hardness approx. 60 HRC
- With precision stripping holes
- For crimping wire ferrules
- Vanadium electric steel, forged, multi stage oil-hardened

General	
Article No.	13 05 160
EAN	4003773071426
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips
Weight	139 g
Dimensions	160 x 59 x 19 mm
Reach	no
RohS	no

Technical details	
Cutting capacities medium hard wire (diameter)	Ø 2.5
Cutting capacities hard wire (diameter)	Ø 1.6
Stripping capacities in square millimetres	0.5 — 0.75 / 1.5 / 2.5 mm <sup>2</sup>

Classification	
eCl@ss 5.1.4	21040302
ETIM 5.0	EC000163
ETIM 6.0	EC000163
proficl@ss 6.0	AAA002c003
UNSPSC 13.1	27112148


technical change and errors excepted

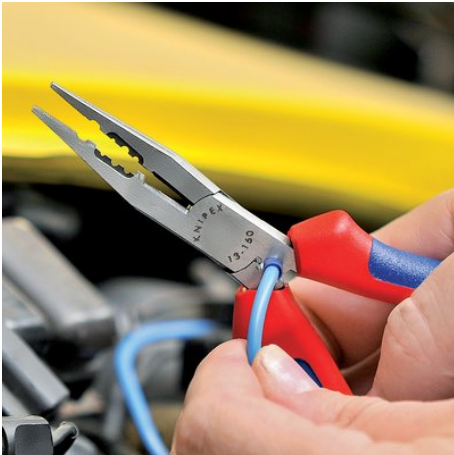


Stripping



Cutting Edges

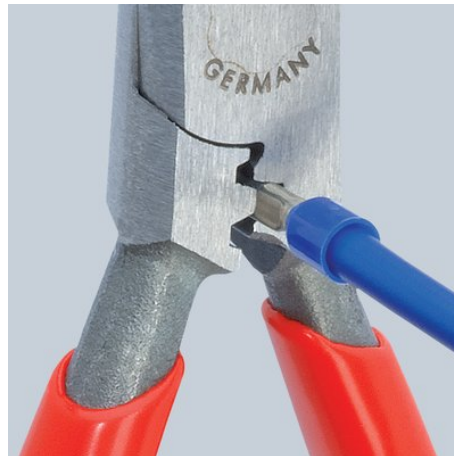

Crimping 0.5 to 2.5 mm<sup>2</sup>

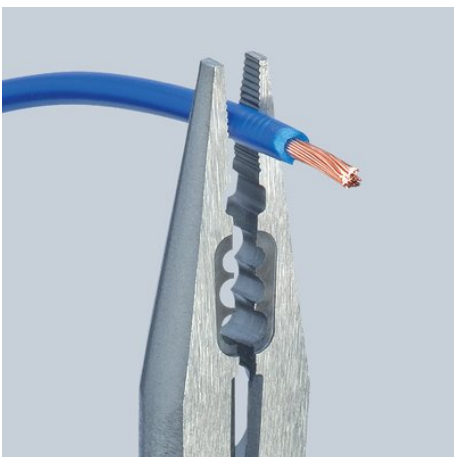

Gripping

