

Product information

22 02 140

Round Nose Pliers

DIN ISO 5745

- For bending wire loops
- Round, short jaws; finely ground
- Smooth tips
- Special tool steel, forged, oil-hardened




General

Article No.	22 02 140
EAN	4003773043430
Pliers	black atramentized
Head	polished
Handles	with multi-component grips
Weight	129 g
Dimensions	140 x 57 x 18 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Jaw thickness (joint) (T1)	9.5 mm
Tips thickness (T2)	2.5 mm
Jaw length (L3)	28.0 mm
Head width (W3)	16.5 mm

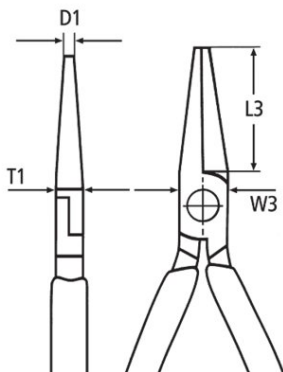

Classification	
eCl@ss 5.1.4	21040301
ETIM 5.0	EC000834
ETIM 6.0	EC000834
proficl@ss 6.0	AAA005c004
UNSPSC 13.1	27112125

technical change and errors excepted

