

## Product information

**22 05 140**

- For bending wire loops
- Round, short jaws; finely ground
- Smooth tips
- Special tool steel, forged, oil-hardened

## Round Nose Pliers

DIN ISO 5745




### General

Article No.	22 05 140
EAN	4003773042891
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips
Weight	127 g
Dimensions	140 x 58 x 18 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

### Technical details

Jaw thickness (joint) (T1)	9.5 mm
Tips thickness (T2)	2.5 mm
Jaw length (L3)	28.0 mm
Head width (W3)	16.5 mm

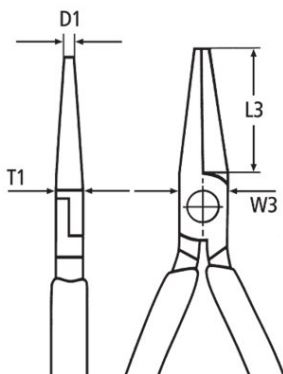

<b>Classification</b>	
eCl@ss 5.1.4	21040301
ETIM 5.0	EC000834
ETIM 6.0	EC000834
proficl@ss 6.0	AAA005c004
UNSPSC 13.1	27112125

*technical change and errors excepted*

