

Product information

23 01 140

Flat Nose Pliers with cutting edges (Precision Mechanics Pliers)


DIN ISO 5745

- Suitable for finer gripping and cutting work
- Flat, long jaws, tapering
- Cutting edges additionally induction-hardened, cutting edge hardness approx. 60 HRC
- High-grade special tool steel, forged, multi stage oil-hardened



General	
Article No.	23 01 140
EAN	4003773041290
Head	polished
Handles	plastic coated
Weight	75 g
Dimensions	140 x 52 x 12 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details	
Cutting capacities soft wire (diameter)	Ø 2.5 mm
Cutting capacities medium hard wire (diameter)	Ø 1.6 mm
Jaw thickness (joint) (T1)	7.0 mm
Tips width (W4)	3.0 mm
Tips thickness (D1)	4.5 mm
Jaw length (L3)	35.0 mm
Head width (W3)	12.5 mm

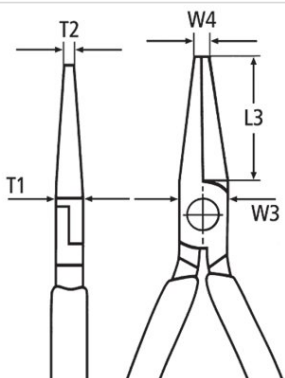



Classification	
eCl@ss 5.1.4	21040301
ETIM 5.0	EC000833
ETIM 6.0	EC000833
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112126

technical change and errors excepted