

## Product information

# 25 01 140

## Snipe Nose Side Cutting Pliers (Radio Pliers)

DIN ISO 5745


- Suitable for finer gripping and cutting work
- Half-round, long, tapered jaws
- Knurled gripping surfaces
- With cutting edges for soft, medium-hard and hard wire
- Cutting edges additionally induction-hardened, cutting edge hardness approx. 61 HRC
- Straight jaws
- Vanadium electric steel, forged, multi stage oil-hardened



General	
Article No.	25 01 140
EAN	4003773033158
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	90 g
Dimensions	140 x 53 x 12 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details	
Cutting capacities medium hard wire (diameter)	Ø 2.5 mm
Cutting capacities hard wire (diameter)	Ø 1.6 mm
Jaw thickness (joint) (T1)	8.0 mm
Tips width (W4)	2.5 mm
Tips thickness (T2)	2.0 mm
Jaw length (L3)	42.0 mm
Head width (W3)	15 mm

**Technical details**

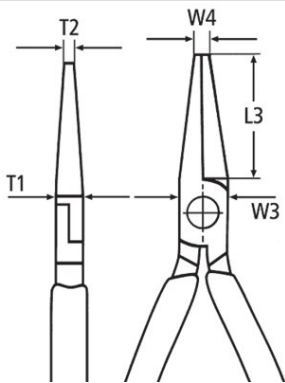

**Classification**

eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

*technical change and errors excepted*