

Product information

31 15 160

Flat Nose Pliers


(Needle-Nose Pliers)

- Precision pliers for very exact assembly, bending and adjusting work
- With extra long jaws: length of jaws 55.0 mm
- Smooth ground gripping surfaces
- Edges carefully deburred
- Straight jaws
- Chrome vanadium electric steel, forged, oil-hardened



General	
Article No.	31 15 160
EAN	4003773016465
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips
Weight	124 g
Dimensions	160 x 56 x 19 mm
Reach	no
RohS	no

Technical details	
Jaw thickness (joint) (T1)	7.5 mm
Tips width (W4)	1.8 mm
Tips thickness (T2)	2.5 mm
Jaw length (L3)	55.0 mm
Head width (W3)	16.0 mm

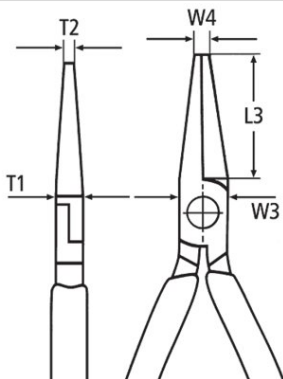



Classification	
eCl@ss 5.1.4	21040301
ETIM 5.0	EC000833
ETIM 6.0	EC000833
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112126

technical change and errors excepted