

Product information

38 25 200

- High bending strength of the pliers tips
- 40° bent, half-round jaws
- Vanadium electric steel; forged, oil-hardened

Mechanics' Pliers

DIN ISO 5745




General

Article No.	38 25 200
EAN	4003773043669
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips
Weight	209 g
Dimensions	200 x 52 x 19 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Jaw thickness (joint) (T1)	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.5 mm
Jaw length (L3)	73.0 mm
Head width (W3)	17.5 mm
Head angle	40 °

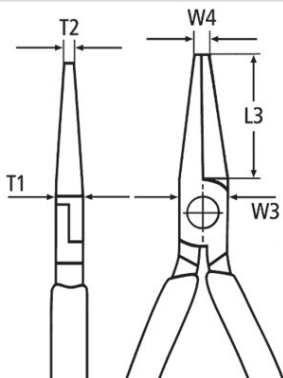



Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112104

technical change and errors excepted