

Product information

 
38 91 200

Mechanics' Pliers

DIN ISO 5745



- High bending strength of the pliers tips
- Gripping surfaces cross-hatched, knurled
- 45° angled, half-round, long jaws, also suitable for gripping spark plugs and round components (spark plug cover "grabber")
- Vanadium electric steel; forged, oil-hardened




General

Article No.	38 91 200
EAN	4003773017219
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	177 g
Dimensions	200 x 51 x 13 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Jaw thickness (joint) (T1)	9.5 mm
Tips thickness (T2)	2.5 mm
Jaw length (L3)	73.0 mm
Head width (W3)	17.5 mm
Head angle	45 °

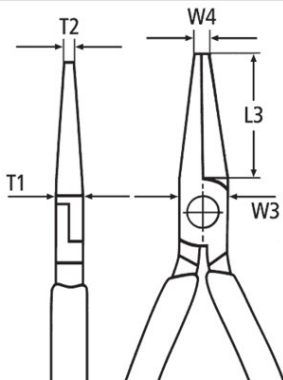

Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112104

technical change and errors excepted

