

Product information

62 12 120

Electronics Oblique Cutting Nipper

DIN ISO 9654

- With cutting edges for soft and medium hard wire
- Without bevel, for flush cutting
- Low-friction double spring for gentle and even opening
- Sturdy, zero backlash box joint
- The polish together with a fine film of oil offer effective rust protection - no circuit faults caused by peeling chrome from plated tools
- Cutters additionally laser hardened, cutter hardness at least 56 HRC
- Ball bearing chrome steel, oil hardened




General

| | |
|-------------|----------------------------|
| Article No. | 62 12 120 |
| EAN | 4003773048008 |
| Head | polished |
| Handles | with multi-component grips |
| Weight | 70 g |
| Dimensions | 120 x 67 x 17 mm |
| Standard | DIN ISO 9654 |
| Reach | no |
| RohS | no |

Technical details

| | |
|--|--------------|
| Cutting capacities soft wire (diameter) | Ø 0.3 – 1 mm |
| Cutting capacities medium hard wire (diameter) | Ø 0.7 mm |
| Jaw length (B) | 10 mm |
| Jaw thickness (joint) (D) | 7.5 mm |
| Cutting edge length mm (C) | 17 mm |
| Head width (A) | 11 mm |

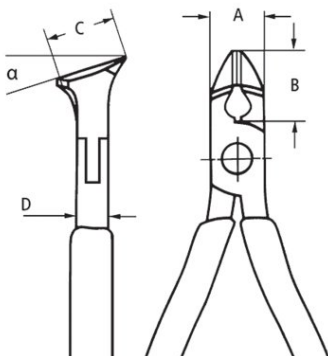

| Classification | |
|-----------------------|------------|
| eCl@ss 5.1.4 | 21040301 |
| proficl@ss 6.0 | AAA947c004 |

technical change and errors excepted

