

## Product information

# 70 01 160

## Diagonal Cutter



DIN ISO 5749

- The indispensable diagonal cutter for all-round use
- High-quality material and precise workmanship for long service life
- Precision cutting edges for soft and hard wire
- Clean cutting of thin copper wires, also at the cutting edge tips
- Cutting edges additionally induction-hardened, cutting edge hardness approx. 62 HRC
- Narrow head style for use in confined areas
- Vanadium electric steel, forged, multi stage oil-hardened



General	
Article No.	70 01 160
EAN	4003773013426
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	171 g
Dimensions	160 x 50 x 13 mm
Standard	DIN ISO 5749
Reach	no
RohS	no
Technical details	
Cutting capacities soft wire (diameter)	Ø 4.0 mm
Cutting capacities medium hard wire (diameter)	Ø 3.0 mm
Cutting capacities hard wire (diameter)	Ø 2 mm
Classification	
eCl@ss 5.1.4	21040302
ETIM 5.0	EC000165
ETIM 6.0	EC000165
proficl@ss 6.0	AAA949c004
UNSPSC 13.1	27112114

*technical change and errors excepted*

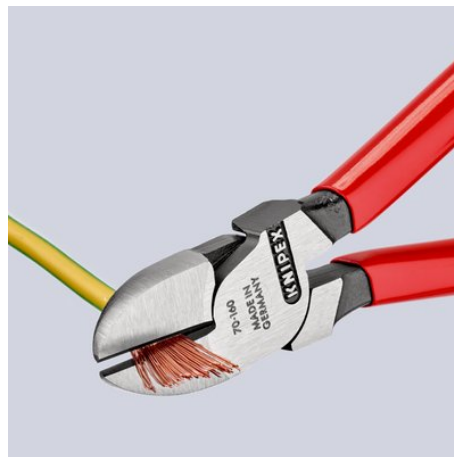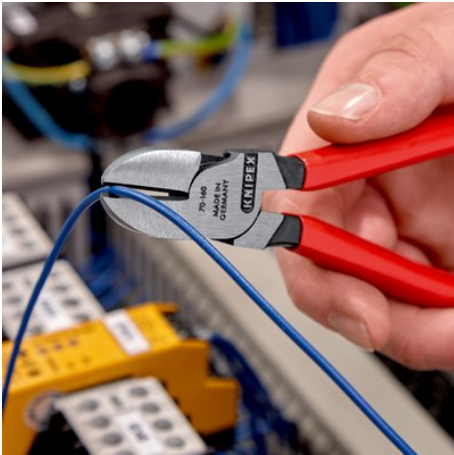

clean cutting of thin copper wires, also at the cutting edge tips