

Product information

86 01 180

Pliers Wrench


Pliers and a wrench in a single tool



- Replaces the need for sets of metric and imperial spanners
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- Increased gripping capacity thanks to two additional setting positions: variable gripping of all widths across flats up to 40 mm
- 10 % less weight with the same stability
- Practical adjustment scale: a laser-cut scale allows the wrench opening to be set before gripping
- Also excellent for gripping, holding, pressing and bending workpieces
- Zero backlash jaw pressure prevents damage to edges of sensitive components
- Fast adjustment by pushing a button directly on the workpiece
- No unintentional shift of the gripping jaws and no slipping of the joint
- Parallel jaws give a more solid grip; its design allows flexible adjustment of all widths up to the specified maximum size
- The ratchet type principle allows quick and easy tightening and release of all bolted connections
- Chrome vanadium electric steel, forged, oil-hardened



General	
Article No.	86 01 180
EAN	4003773084273
Pliers	grey atramentized
Head	polished
Handles	plastic coated
Weight	230 g
Dimensions	180 x 46 x 15 mm
Reach	no
RohS	no
Technical details	
Jaw thickness (joint) (B2)	8.0 mm
Joint thickness (B3)	12.0 mm
Tips thickness (B1)	5.0 mm
Adjustment positions	15
Capacities for nuts	Ø 1 1/2 Inch
Capacities for nuts	40 mm

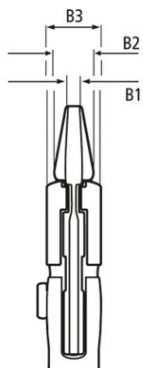

Classification

eCl@ss 5.1.4	21043826
proficl@ss 6.0	AAA936c004

technical change and errors excepted

