


Product information

97 49 05

- Application: non-insulated open plug type connectors (plug width 4.8 + 6.3 mm) 0.5 - 6.0 mm²

Crimping die

For non-insulated open plug-type connectors 4.8 + 6.3 mm

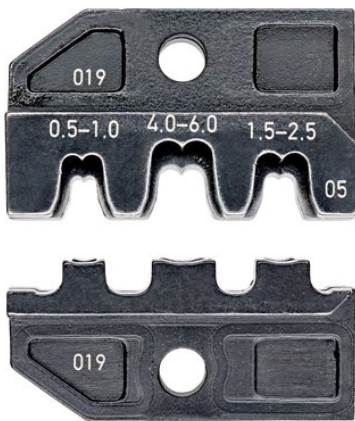

General

Article No.	97 49 05
EAN	4003773030867
Weight	46 g
Dimensions	50 x 10 mm
Reach	yes
RohS	no

Technical details



Applications	non-insulated open plug type connectors (plug width 4.8 + 6.3 mm)
Capacity in square millimetres	0.5 — 6 mm ²
Number of crimping positions	3
AWG	20 — 10

Classification

eCl@ss 5.1.4	21040301
ETIM 5.0	EC000168
ETIM 6.0	EC000168
proficl@ss 6.0	AAA946c003
UNSPSC 13.1	27112820



Accessories

97 49 95

Locator for 97 49 05 ,

technical change and errors excepted