


Product information

97 49 08

- Application: insulated + non-insulated wire ferrules

Crimping die


For insulated and non-insulated wire ferrules

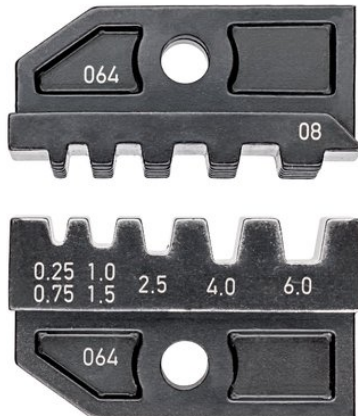

General

Article No.	97 49 08
EAN	4003773030874
Weight	49 g
Dimensions	50 x 17 mm
Reach	no
RohS	no

 Technical details



Applications	insulated and non-insulated wire ferrules
Capacity in square millimetres	0.25 — 6 mm ²
Number of crimping positions	5
AWG	24 — 10

Classification

eCl@ss 5.1.4	21040301
ETIM 5.0	EC000168
ETIM 6.0	EC000168
proficl@ss 6.0	AAA946c003
UNSPSC 13.1	27112820

technical change and errors excepted