


## Product information

**97 49 60**

- Application: turned contacts (HTS + Harting) 0.14 - 4.0 mm<sup>2</sup>

### Crimping die


For turned contacts (HTS + Harting)

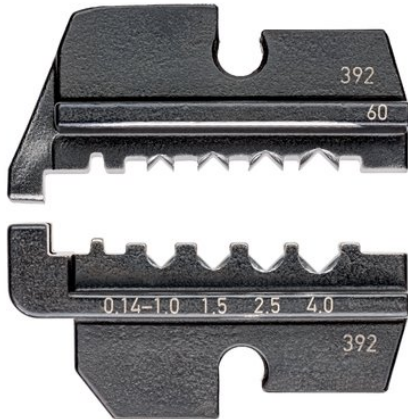

#### General

Article No.	97 49 60
EAN	4003773030928
Weight	53 g
Dimensions	50 x 17 mm
Reach	no
RohS	no

#### Technical details



Applications	turned contacts (HTS + Harting)
Capacity in square millimetres	0.14 — 4 mm <sup>2</sup>
Number of crimping positions	4
AWG	26 — 12

#### Classification

eCl@ss 5.1.4	21040301
ETIM 5.0	EC000168
ETIM 6.0	EC000168
proficl@ss 6.0	AAA946c003
UNSPSC 13.1	27112820



**Accessories**

97 49 90

Locator for 97 49 60 (HTS+Harting),

*technical change and errors excepted*