

# CAB PCQ 303017 T



Sample image

**Order symbol:** CAB PCQ 303017 T

**Product nbr:** 8113048

**Description:** Enclosure. PC



**Remarks:** Smoked transparent cover

**EAN:** 6418074011084

**El. number:**

- Finland: 3421922
- Denmark:
- Sweden: 2539184

**Including:** Base with screws for mounting plate/DIN-rail. internal corner plugs. cover with PUR gasket and CS 12137 cover screws.

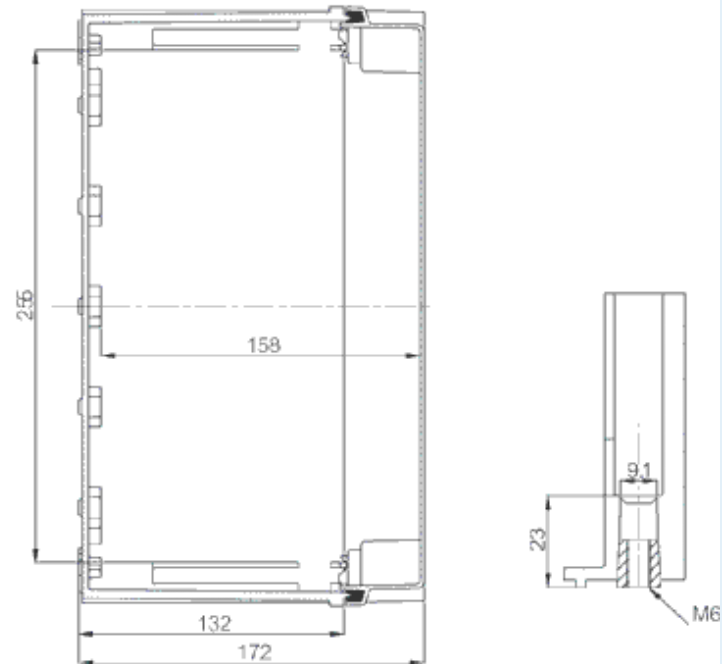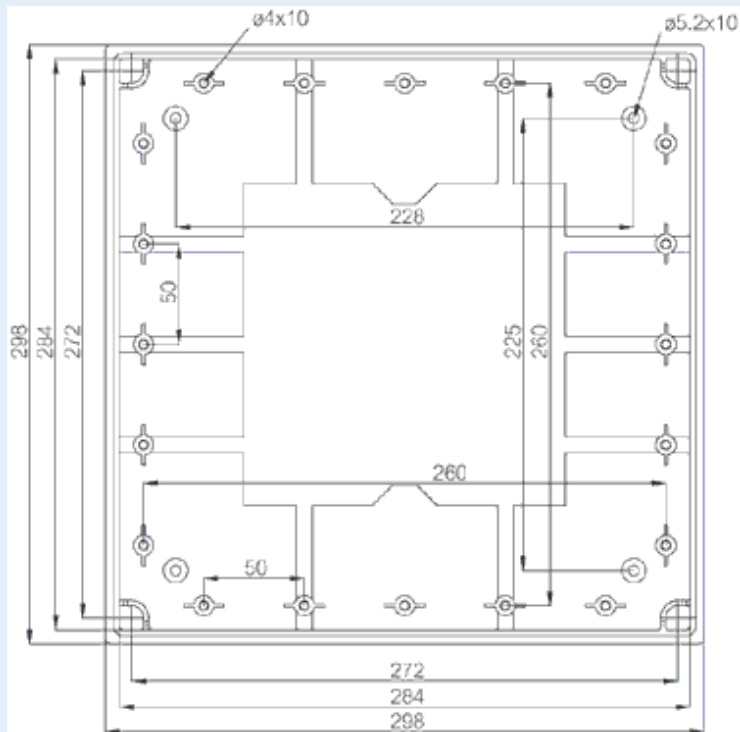

Dimensions:	Height	Width	Depth
mm:	300	300	170
inch:	11.81	11.81	6.69

## Materials:

Material: Polycarbonate

## Accessories:

EKIV 33	Back Panel. for enclosures: (270 x 270 x 1)
PAT 12040	Hinge kit
MB 12225 AL	Swing door kit
FP A 33	Swing-out door/Front panel (aluminum). for enclosures:

Base colour:	RAL 7035 -light grey
Cover colour:	Clear transparent
Gasket material:	Polyurethane

(268 x 268 x 1)

EKIV 27 DIN-35 Mounting rail. for enclosures:  
(266 x 35 x 1)

DRF 33 DIN rail frame kit. for enclosures:

#### Temperatures:

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

#### Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

#### Certificates:

Certificate FI 40848