

# CAB PCQ 604021 T



Sample image

**Order symbol:** CAB PCQ 604021 T

**Product nbr:** 8113078

UL Code: 8143078

UL Name: UL CAB PCQ 604021T

**Description:** Enclosure. PC


**Remarks:** Smoked transparent cover

**EAN:** 6418074011121

**El. number:**

- Finland: 3421926
- Denmark:
- Sweden: 2540109

**Including:** Base with screws for mounting plate/DIN-rail. internal corner plugs. cover with PUR gasket and CS 12137 cover screws.

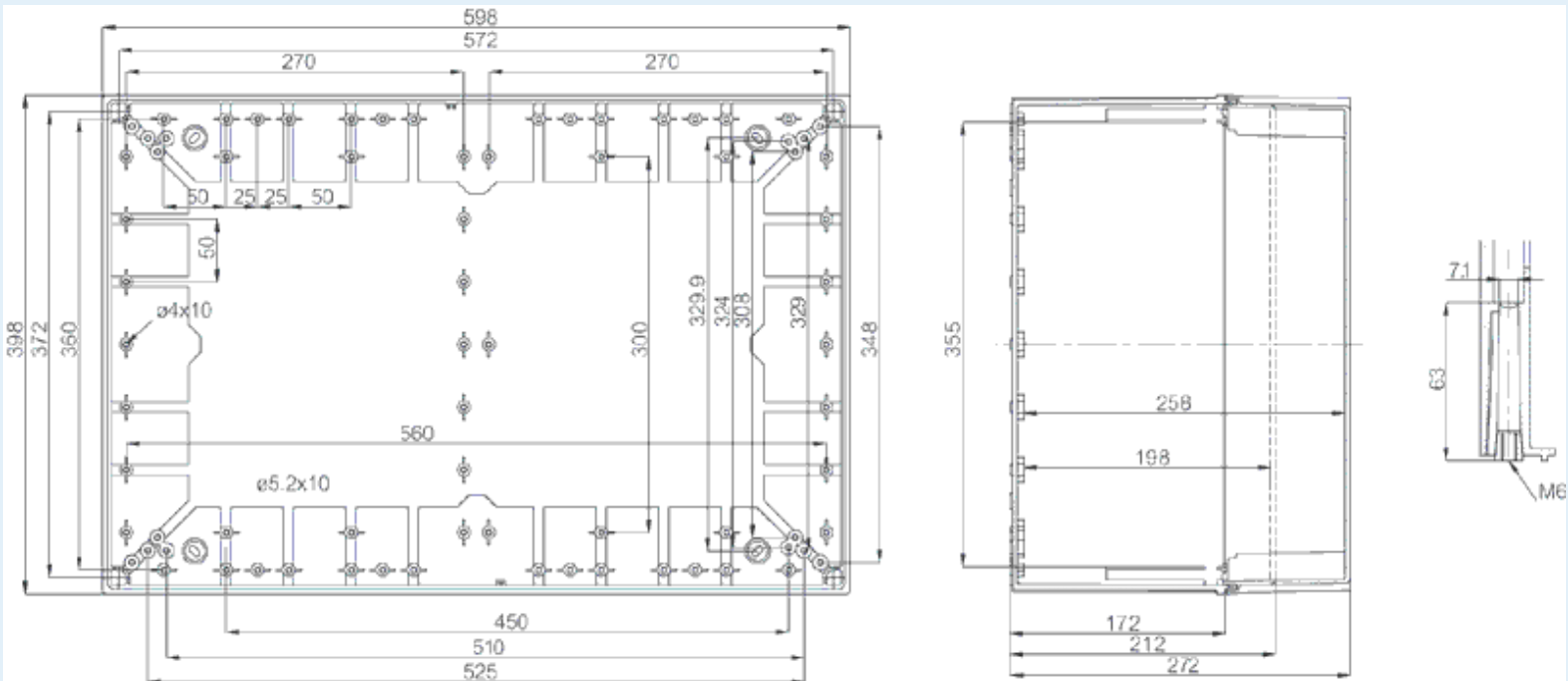

Dimensions:	Height	Width	Depth
mm:	600	400	210
inch:	23.62	15.75	8.27

**Accessories:**

- EKIV 64H Back Panel. for enclosures: (570 x 370 x 1)
- PAT 12040 Hinge kit

**Materials:**

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	Clear transparent
Gasket material:	Polyurethane

MB 12225 AL	Swing door kit
EKIV 37	DIN-35 Mounting rail. for enclosures: (366 x 35 x 1)
DRF 63/64	DIN rail frame kit. for enclosures:
FP A 64	Swing-out door/Front panel (aluminum). for enclosures: (568 x 368 x 1)

**Temperatures:**

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

**Rating:**

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

**Certificates:**

Certificate FI 40848