

# MPMP ARCA 7050

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol:** MPMP ARCA 7050

**Product nbr:** 8120927

**Description:** Mounting plate multiperforated (630x430x2 mm -  $\varnothing$ 3.6 mm)


**Remarks:** Galvanized steel. for size 700x500x300

**EAN:** 6418074089540

**Including:**

**El. number:**

- Finland:
- Denmark:
- Sweden:

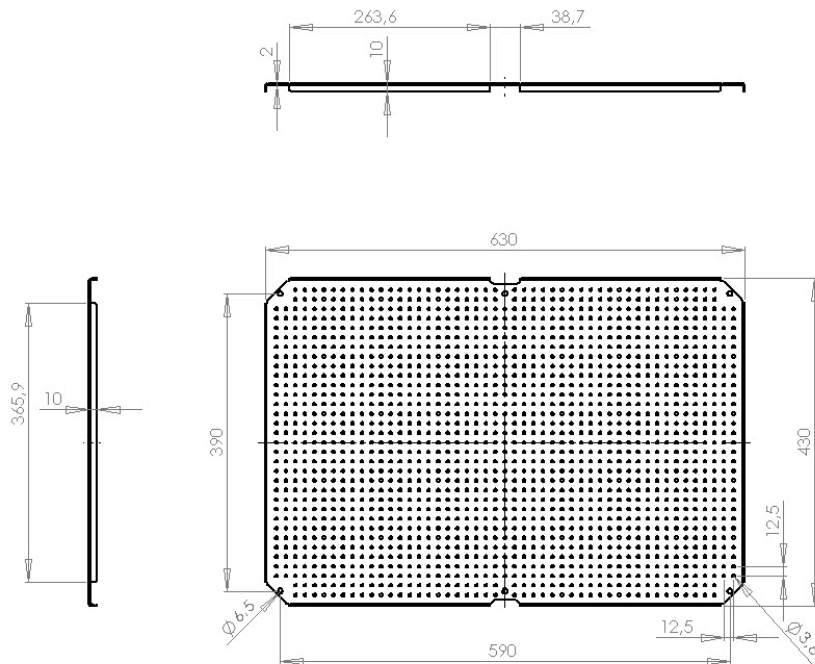

**Dimensions:**

	Height	Width	Depth
mm:	630	430	2
inch:	0	0	0.08

**Materials:**

Material:

Base colour:

Cover colour:

Gasket material:

**Temperatures:**

Temperature °C (short term)::

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

**Rating:**

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation:

Not insulated

Halogen free (DIN/VDE 0472, Part 815):

0

UV resistance:

-

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C:

C

NEMA Class

**Certificates:**