


MPMP ARCA 3020

FIBOX
Enclosing innovations

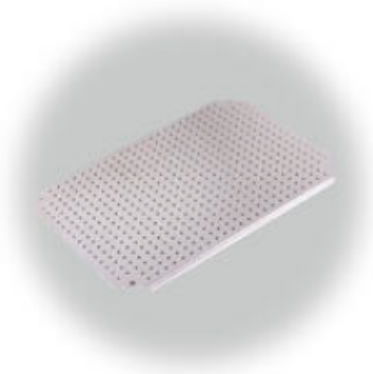

Sample image

Order symbol: MPMP ARCA 3020

EAN: 64 18074089472

Product nbr: 8120920


El. number:

Description: Mounting plate
multiperforated (250x150x2 mm -
ø3.6 mm)

- Finland:
- Denmark:
- Sweden:

Remarks: Galvanized steel. for size
300x200x150

Including:

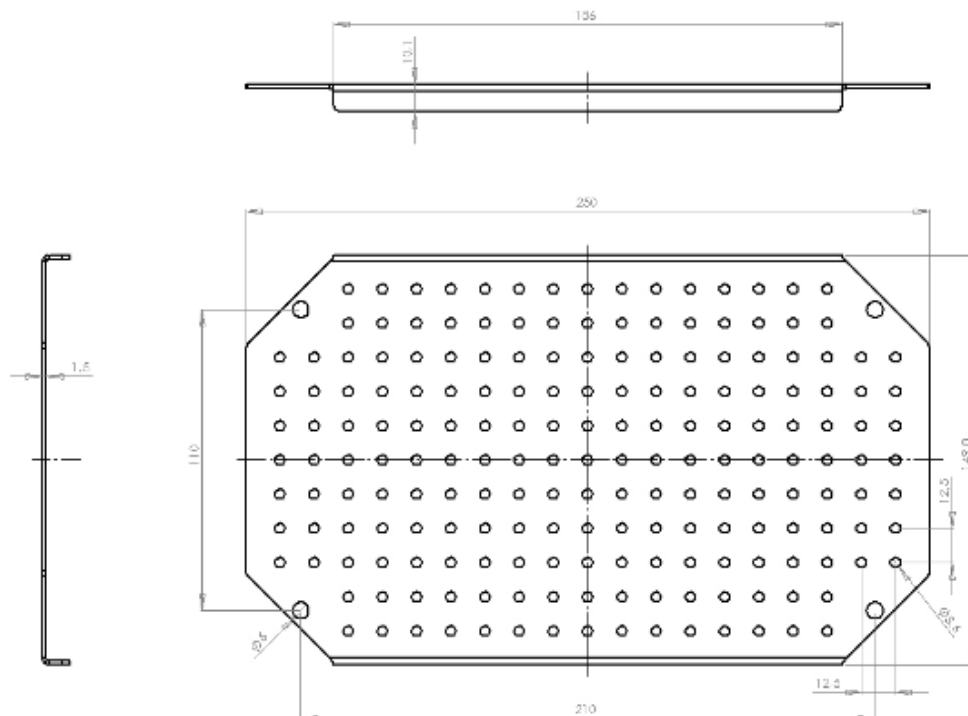

Dimensions:

	Length	Width	Height
mm:		150	250
inch:		0	0

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C:

NEMA Class

Certificates: