

MPMP ARCA 4030



Sample image

Order symbol: MPMP ARCA 4030

Product nbr: 8120922

Description: Mounting plate multiperforated (350x250x2 mm - \varnothing 3.6 mm)


Remarks: Galvanized steel. for size 400x300x150/210

EAN: 6418074089496

Including:

El. number:

- Finland:
- Denmark:
- Sweden:

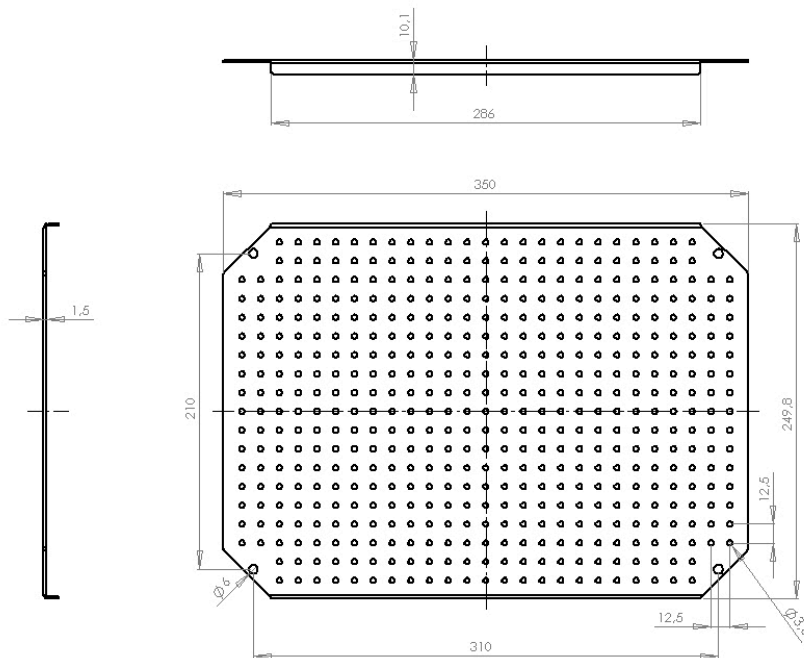

Dimensions:

	Height	Width	Depth
mm:	350	250	2
inch:	0	0	0.08

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C: C

NEMA Class

Temperatures:

Temperature °C (short term)::

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Certificates: