


# MPP ARCA 5040

**FIBOX**  
Enclosing innovations

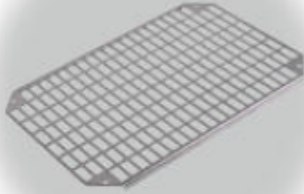

Sample image

**Order symbol:** MPP ARCA 5040

**Product nbr:** 8120755

**Description:** Mounting plate perforated (450x350x2 mm - 26x11 mm)


**Remarks:** Galvanized steel. for size 500x400x210

**Including:**

**EAN:** 6418074082763

**El. number:**

- Finland: 3423837
- Denmark:
- Sweden:

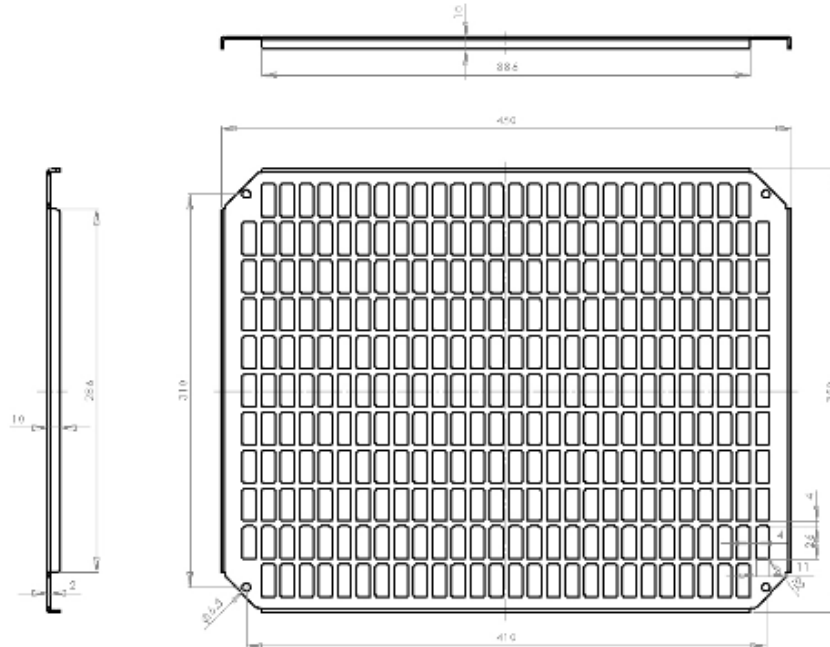

**Dimensions:**

	Length	Width	Height
mm:		350	450
inch:		13.78	17.72

**Materials:**

Material: \_\_\_\_\_

Base colour: \_\_\_\_\_

Cover colour: \_\_\_\_\_

Gasket material: \_\_\_\_\_

**Temperatures:**

Temperature °C (short term): \_\_\_\_\_

Temperature °C (continuous): \_\_\_\_\_

Temperature °F (short term): \_\_\_\_\_

Temperature °F (continuous): \_\_\_\_\_

**Rating:**

Ingress protection (EN 60529): \_\_\_\_\_

Impact Resistance (EN 62262): \_\_\_\_\_

Electrical insulation: \_\_\_\_\_ Not insulated

Halogen free (DIN/VDE 0472, Part 815): \_\_\_\_\_ 0

UV resistance: \_\_\_\_\_ -

Flammability Rating: \_\_\_\_\_

Glow Wire Test (IEC 695-2-1) °C: \_\_\_\_\_

NEMA Class \_\_\_\_\_

**Certificates:**