


# MPP ARCA 8060

**FIBOX**  
Enclosing innovations

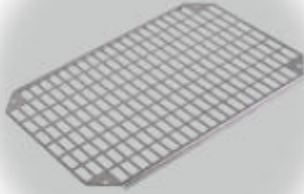

Sample image

**Order symbol:** MPP ARCA 8060

**EAN:** 6418074082800

**Product nbr:** 8120759


**El. number:**

**Description:** Mounting plate perforated (730x530x2 mm - 26x11 mm)

- Finland: 3423847
- Denmark:
- Sweden:

**Remarks:** Galvanized steel. for size 800x600x300

**Including:**

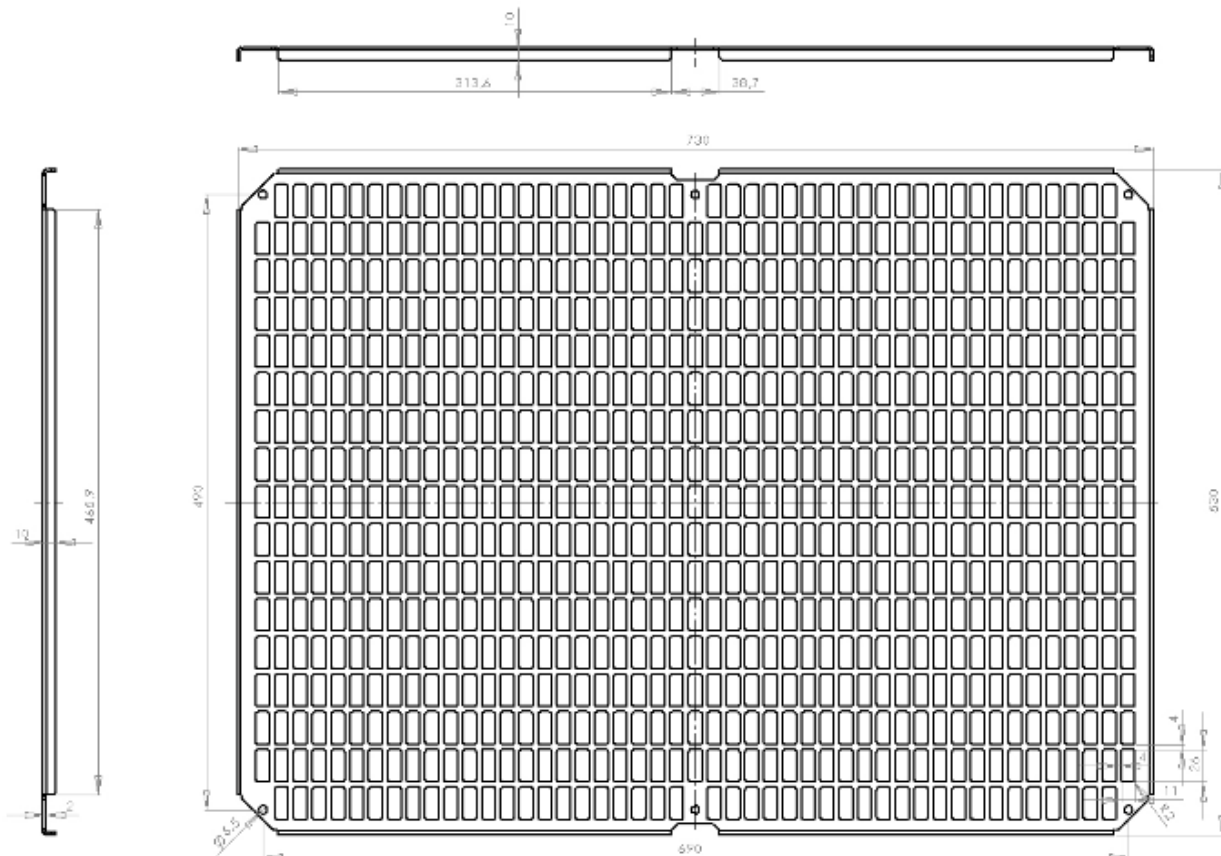

**Dimensions:**

	Length	Width	Height
mm:		530	730
inch:		0	0

**Materials:**

Material:

Base colour:

Cover colour:

Gasket material:

**Temperatures:**

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

**Rating:**

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C:

NEMA Class

**Certificates:**