


TM 1625

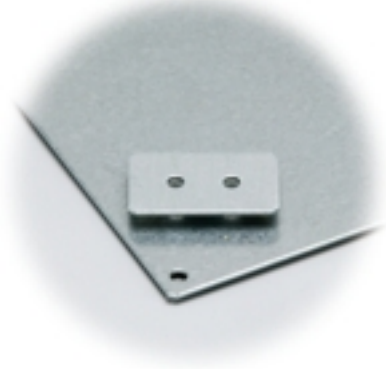

Sample image

Order symbol: TM 1625

Product nbr: 9512018

Description: Back Panel. for enclosures:

Remarks: 250x160x90-250x160x150

Including:

EAN: 6418074034076

El. number:

- Finland: 3423928
- Denmark: 8212004029
- Sweden: 2536165

TM_1624-2330

Dimensions:	Height	Width	Depth
mm:	151	214	1
inch:	5.94	8.43	0.04

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation:

Not insulated

Halogen free (DIN/VDE 0472, Part 815):

0

UV resistance:

-

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C:

C

NEMA Class

Temperatures:

Temperature °C (short term)::

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Certificates: