


EB4-IR/N

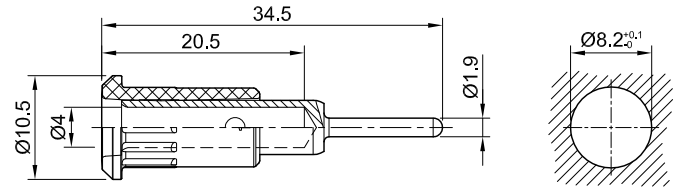

Item number 64.3011-*

Insulated, \varnothing 4 mm, rigid. Machined brass. The socket is pressed into predrilled panels of plastic, metal etc. Round connecting pin 1.9 mm.

Technical data	
Diameter of plug system	4 mm
Rated Values	30 V, 25 A / 60 V, 25 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	20 21 22 23 24 25 26 27 28 29
Component parts	I-EB4-I; B-EB4-IR_NI