

Technical Characteristics

Part Number

Han[®] 1A Kit

Hood	Top Entry
Housing	Locking Lever Coupler
Material	Polyamide Plastic
Protection Degree	IP65
Temp Rating	-30 to +90C
Cable Gland	Plastic
Cable Diameter	5.7 – 10mm
Insert	3+GND
Screw Terminals	18-14AWG
Wire Strip Length	7.5mm
Mating Cycles	>100
Flammability	V-0

73 10 100 0021




* Mounting Frame Included

Electrical Characteristics

Rated Current	10amps
Rated Voltage acc. UL	250V
Rated Impulse Voltage	6kV

Drawings and Assembly Information

Dimensions in mm

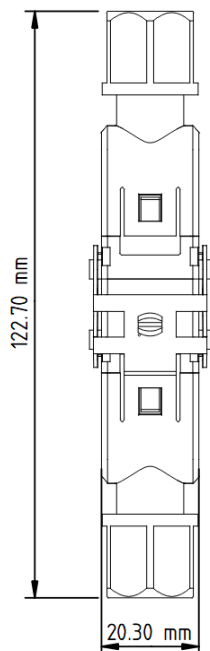

Tooling and Torque Values		
Type	Tool	Torque (Nm)
Terminal Screws (M3)	Slotted 0.4 x 2.5	0.25

Kit Contents	
Male Insert	09 10 003 2606
Female insert	09 10 003 2706
Hood & Gland (x2)	09 10 000 0400
Lever	09 10 000 5200
Mounting Frame	09 10 000 9908

For further information, please reach out to techsupportUS@HARTING.com