

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0150320209](#)  
**Status:** **Active**  
**Overview:** FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers  
**Description:** 0.30mm Pitch, Premo-Flex FPC Jumper with Latching Ears, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 9 Circuits

**Documents:**

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)  
[Product Specification 150320001-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family Cable  
 Series [15032](#)  
 Crimp Quality Equipment Yes  
 Overview [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)  
 Product Name Premo-Flex FFC Jumper  
 UPC 195842789081

**Physical**

Cable Length 51.00mm  
 Circuits (Loaded) 9  
 Circuits (maximum) 9  
 Contact Layout Type A (same side)  
 Material - Plating Mating Gold  
 Packaging Type Bag  
 Pitch - Mating Interface 0.30mm  
 Temperature Range - Operating -40° to +105°C  
 Wire Size AWG N/A  
 Wire/Cable Type Flexible Printed Circuitry


**Electrical**

Current - Maximum per Contact 0.2A  
 Voltage - Maximum N/A

**Material Info**

**Reference - Drawing Numbers**

Product Specification 150320001-000  
 Sales Drawing 150320001-000

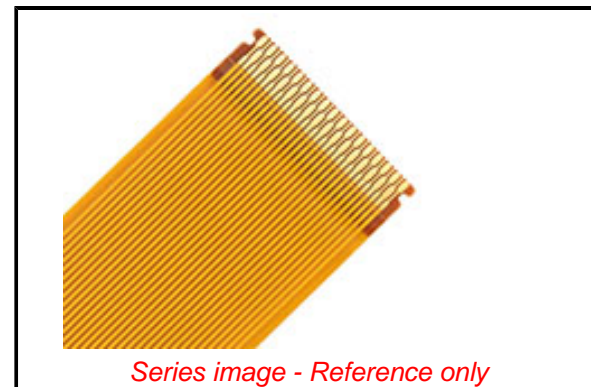

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 D(2022)4187-DC (10  
 June 2022)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[15032 Series](#)

**Mates With**

Easy-On FPC Connector [503566](#)