

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150310261](#)
Status: **Active**
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 0.30mm Pitch Premo-Flex FPC Jumper with Notches, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 61 Circuits

Documents:

Drawing (PDF)	Datasheet (PDF)
Product Specification 150310001-000 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Cable
Series	15031
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	195842786653

Physical

Cable Length	51.00mm
Circuits (Loaded)	61
Circuits (maximum)	61
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Packaging Type	Bag
Pitch - Mating Interface	0.30mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flexible Printed Circuitry


Electrical

Current - Maximum per Contact	0.2A
Voltage - Maximum	N/A

Material Info

Reference - Drawing Numbers

Product Specification	150310001-000
Sales Drawing	150310001-000

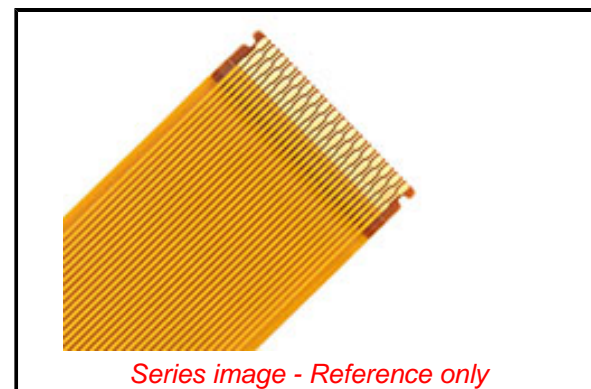

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[15031 Series](#)

Mates With

Easy-On FPC Connector [5047546100](#)