

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0150310215](#)  
**Status:** **Active**  
**Overview:** FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers  
**Description:** 0.30mm Pitch Premo-Flex FPC Jumper with Notches, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 15 Circuits

**Documents:**

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)  
[Product Specification 150310001-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

|                         |   |
|-------------------------|---|
| Product Family          | Cable   |
| Series                  | <a href="#">15031</a>   |
| Crimp Quality Equipment | Yes   |
| Overview                | <a href="#">FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers</a> |
| Product Name            | Premo-Flex FFC Jumper   |
| UPC                     | 195842784550  |

**Physical**

|                               |                            |
|-------------------------------|----------------------------|
| Cable Length                  | 51.00mm                    |
| Circuits (Loaded)             | 15                         |
| Circuits (maximum)            | 15                         |
| Contact Layout Type           | A (same side)              |
| Material - Plating Mating     | Gold                       |
| Packaging Type                | Bag                        |
| Pitch - Mating Interface      | 0.30mm                     |
| Temperature Range - Operating | -40° to +105°C             |
| Wire Size AWG                 | N/A                        |
| Wire/Cable Type               | Flexible Printed Circuitry |


**Electrical**

|                               |      |
|-------------------------------|------|
| Current - Maximum per Contact | 0.2A |
| Voltage - Maximum             | N/A  |

**Material Info**

**Reference - Drawing Numbers**

|                       |               |
|-----------------------|---------------|
| Product Specification | 150310001-000 |
| Sales Drawing         | 150310001-000 |

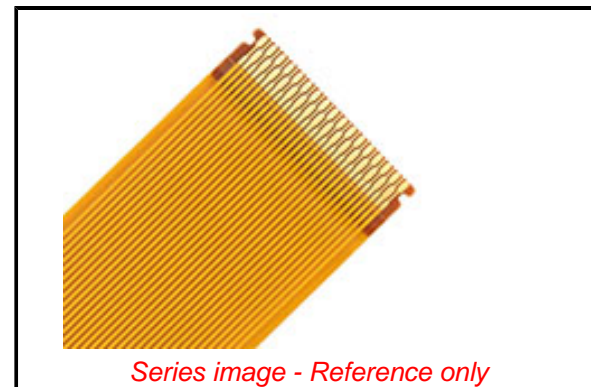

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[15031 Series](#)

**Mates With**

Easy-On FPC Connector [5047541500](#)