


# NEMA 4 CONSOLES/ OPERATOR INTERFACE PANELS WITH SLOPED TOP

**NEW**

## SCE-ELJ CONSOLES

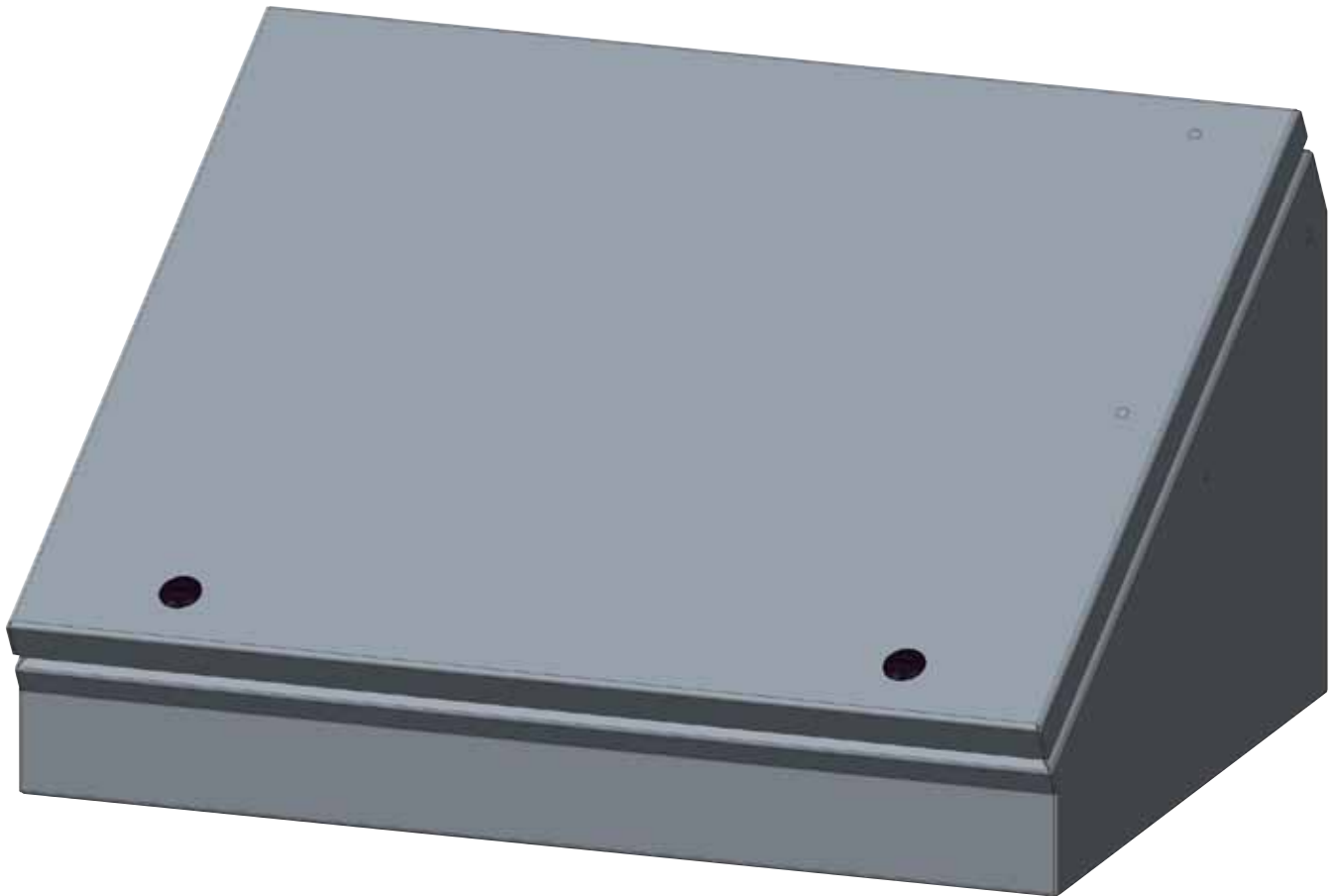

SCE-8C16ELJ, console with  
8 x 16" sloped top cover,  
7.09 H x 7.44" depth.



- 0.063" Carbon Steel
- Seams Continuously Welded and Ground Smooth
- Flange Trough Collar Around all Sides of Door Opening
- Oil-Resistant Gasket
- Standoffs Provided for Mounting Optional Sub-Panels
- Polyamide Hinges—Easily Removed for Machining
- Door Opens 180°
- Provisions for Cable Door Stops on SCE-12C, SCE16C and SCE-20C Models
- Black Mini Quarter Turn Latches
- Latches are Opened or Closed with a Screwdriver
- Sealing Washers and Hole Plugs Included
- Ground Stud on Door and Body
- Mounting Holes in Bottom

Designed to house electrical and electronic controls, instruments, and components. The SCE-ELJ provides protection from dust, dirt, oil and water. These consoles can be used indoors or outdoors and can be mounted on either of two sides to give a control surface inclined 30° or 60°. They can also be mounted on desks, machines, or pedestals. Finished in ANSI-61 gray powder coating inside and out, optional sub-panels are powder coated white.

### Industry Standards—IS2

NEMA Type 4, 12 and 13  
UL Listed Type 4 and 12  
CSA Type 4 and 12  
IEC 60529 IP 66

**NEW**

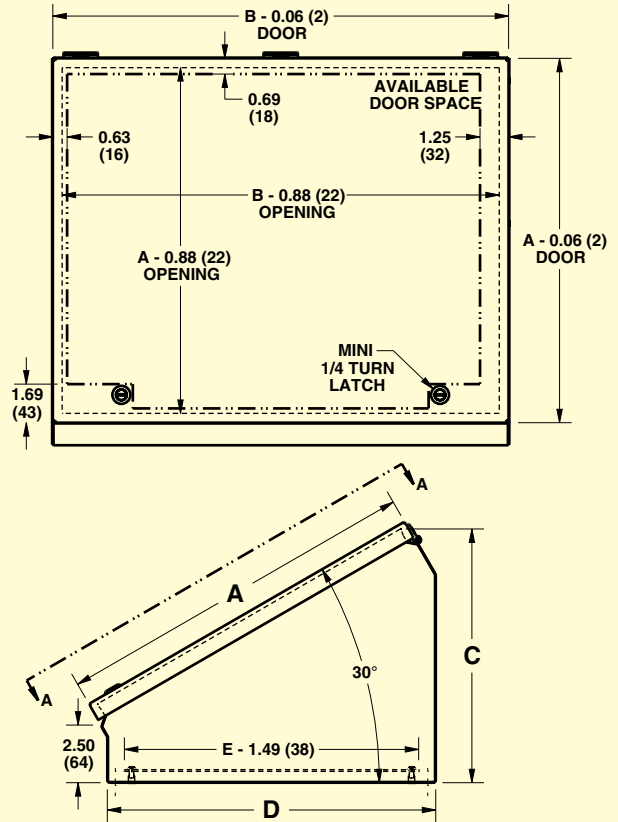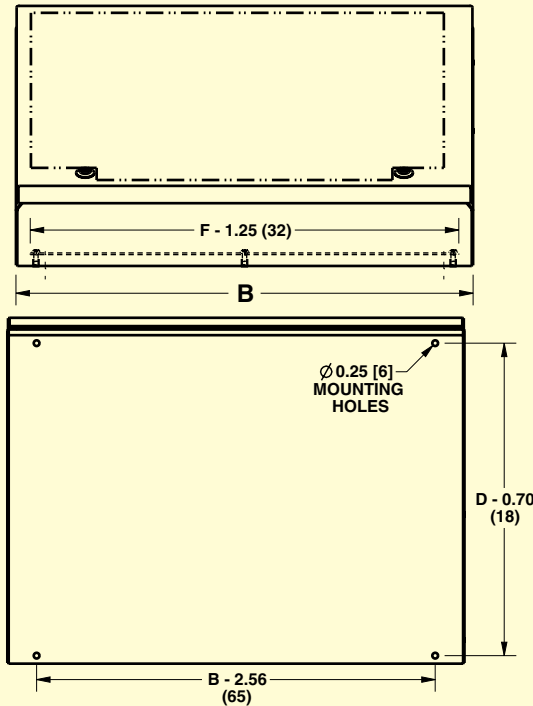

Provisions for cable stops on door and body when "A"  $\geq$  12.00 (305)  
 Latch Notes: One latch centered on door horizontally if "B"  $\leq$  14.00 (356)  
 Two latches located 3.00 (76) from right and left side of door if "B" > 14.00 (356)  
 Optional Sub-Panel Notes: Provisions only for sub-panel in bottom.

Ø = diameter      Dimensions: inch (mm)

**To Order** visit [omega.com/sce-elj](http://omega.com/sce-elj) for Pricing and Details

MODEL NO.	SLOPE TOP HEIGHT A inch	WIDTH B inch	HEIGHT C inch	BASE DEPTH D inch	SUB-PANEL *	DEPTH E inch	WIDTH F inch
SCE-8C8ELJ	8	8	7.09	7.44	SCE-8P8C	6	6.75
SCE-8C12ELJ	8	12	7.09	7.44	SCE-8P12C	6	10.75
SCE-8C16ELJ	8	16	7.09	7.44	SCE-8P16C	6	14.75
SCE-8C20ELJ	8	20	7.09	7.44	SCE-8P20C	6	18.75
SCE-12C12ELJ	12	12	9.09	10.91	SCE-12P12C	9.5	10.75
SCE-12C16ELJ	12	16	9.09	10.91	SCE-12P16C	9.5	14.75
SCE-12C20ELJ	12	20	9.09	10.91	SCE-12P20C	9.5	18.75
SCE-12C24ELJ	12	24	9.09	10.91	SCE-12P24C	9.5	22.75
SCE-16C16ELJ	16	16	11.09	14.37	SCE-16P16C	12.88	14.75
SCE-16C20ELJ	16	20	11.09	14.37	SCE-16P20C	12.88	18.75
SCE-16C24ELJ	16	24	11.09	14.37	SCE-16P24C	12.88	22.75
SCE-20C20ELJ	20	20	13.09	17.83	SCE-20P20C	16.38	18.75
SCE-20C24ELJ	20	24	13.09	17.83	SCE-20P24C	16.38	22.75

\* Sub-panel sold separately.

**ACCESSORIES**

MODEL NO.	DESCRIPTION
SCE-CBL15	15" 135° door stop for SCE-12C and SCE-16C consoles
SCE-CBL20	20" 135° door stop for SCE-20C consoles
SCE-MINIQL	Padlocking latch cover (quantity 1)

Ordering Examples: SCE-8C12ELJ, operator control panel with sloped top front, 8 H x 12" W surface panel.  
 SCE-16C20ELJ, operator interface panel, 16 H x 20" W, SCE-16P20C, sub-panel, and SCE-CBL15, door stop - holding sloped top 135° open.