



Standard Quick Wire Thermocouple Connector Quick Wire Plug & Socket JS-K-MQ+FQ Type K JIS

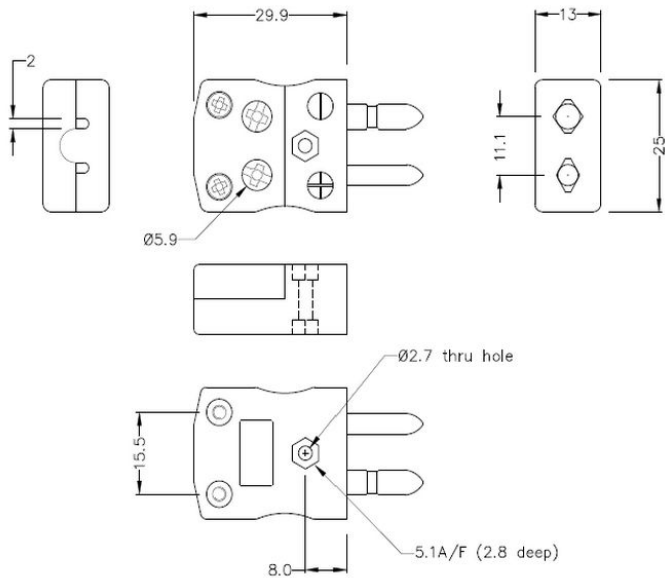

Standard in-line Plug - Quick Wire
(dimensions in mm)

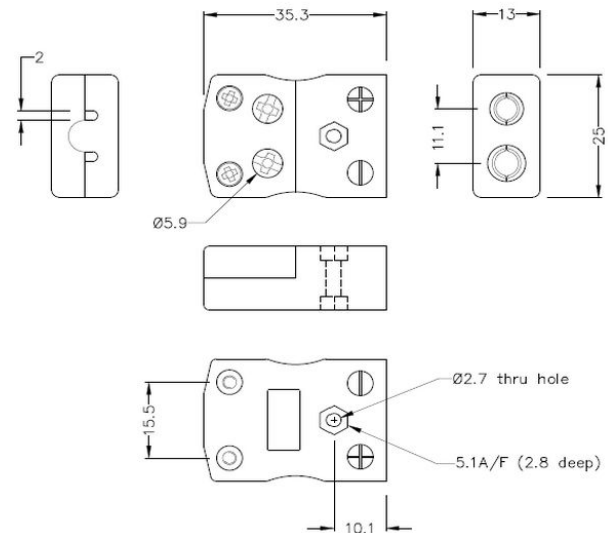

Standard in-line Socket - Quick Wire
(dimensions in mm)

Product Code	XF-1737-FAR
General Description	Easy 'jab-in' connection for rapid termination, contacts are polarised to prevent incorrect connection
Thermocouple Type	K JIS
Connector Size	Standard
Connector Type	Quick Wire Plug & Socket
Colour	Blue
Max. Temperature	220°C
Pins	Solid Round Plns
+Positive Contact	Nickel Chromium

-Negative Contact	Nickel Alloy
Standards Met	BS EN 50212:1997. RoHS

