


Datasheet

IEC PTFE Insulated Twin Twisted Pair Thermocouple Cable

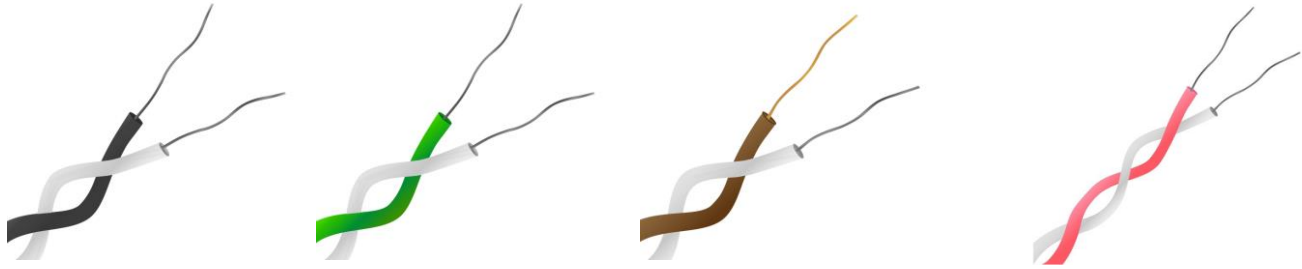

- PTFE twin twisted pair for extending or making simple thermocouples
- Single pair of PTFE insulated conductors twisted together
- Good mechanical strength and flexibility, resistant to oils, acids and other adverse fluids
- Suitable for steam & pressure applications, autoclaves, sterilizers etc.
- Tolerance Class 1 for optimum accuracy
- Insulation rating -75°C to 260°C
- Colour coded to IEC-584-3

Type	Conductors	Reel Length	Manufacturers Code	Order Code
J	1/0.2mm	25m	WJ-244-D	XF-242-FAR
J	1/0.2mm	50m	WJ-244-D	XF-1261-FAR
J	1/0.2mm	100m	WJ-244-D	XF-1793-FAR
J	1/0.315mm	10m	WJ-245-D	XF-1617-FAR
J	1/0.315mm	25m	WJ-245-D	XF-1618-FAR
J	1/0.315mm	50m	WJ-245-D	XF-1619-FAR
J	1/0.315mm	100m	WJ-245-D	XF-1620-FAR
J	1/0.508mm	10m	WJ-246-D	XF-1624-FAR
J	1/0.508mm	25m	WJ-246-D	XF-1621-FAR
J	1/0.508mm	50m	WJ-246-D	XF-1622-FAR
J	1/0.508mm	100m	WJ-246-D	XF-1623-FAR
J	7/0.2mm	10m	WJ-243-D	XF-1613-FAR
J	7/0.2mm	25m	WJ-243-D	XF-1614-FAR
J	7/0.2mm	50m	WJ-243-D	XF-1615-FAR
J	7/0.2mm	100m	WJ-243-D	XF-1616-FAR
K	1/0.2mm	10m	WK-200-D	XF-1308-FAR
K	1/0.2mm	25m	WK-200-D	XF-243-FAR
K	1/0.2mm	50m	WK-200-D	XF-536-FAR
K	1/0.2mm	100m	WK-200-D	XF-537-FAR
K	1/0.315mm	10m	WK-201-D	XF-1817-FAR
K	1/0.315mm	25m	WK-201-D	XF-1263-FAR
K	1/0.315mm	50m	WK-201-D	XF-1256-FAR
K	1/0.315mm	100m	WK-201-D	XF-1776-FAR
K	1/0.508mm	10m	WK-202-D	XF-1815-FAR
K	1/0.508mm	25m	WK-202-D	XF-1268-FAR
K	1/0.508mm	50m	WK-202-D	XF-1251-FAR
K	1/0.508mm	100m	WK-202-D	XF-1798-FAR
K	7/0.2mm	10m	WK-303-D	XF-1654-FAR
K	7/0.2mm	25m	WK-303-D	XF-1653-FAR

K	7/0.2mm	50m	WK-303-D	XF-1655-FAR
K	7/0.2mm	100m	WK-303-D	XF-1785-FAR
T	1/0.2mm	10m	WT-300-D	XF-1267-FAR
T	1/0.2mm	25m	WT-300-D	XF-244-FAR
T	1/0.2mm	50m	WT-300-D	XF-538-FAR
T	1/0.2mm	100m	WT-300-D	XF-539-FAR
T	1/0.315mm	10m	WT-301-D	XF-1695-FAR
T	1/0.315mm	25m	WT-301-D	XF-1693-FAR
T	1/0.315mm	50m	WT-301-D	XF-1694-FAR
T	1/0.315mm	100m	WT-301-D	XF-1696-FAR
T	7/0.2mm	10m	WT-303-D	XF-1702-FAR
T	7/0.2mm	25m	WT-303-D	XF-1701-FAR
T	7/0.2mm	50m	WT-303-D	XF-1703-FAR
T	7/0.2mm	100m	WT-303-D	XF-1704-FAR
N	7/0.2mm	10m	WN-140-D	XF-1820-FAR
N	7/0.2mm	25m	WN-140-D	XF-1792-FAR
N	7/0.2mm	50m	WN-140-D	XF-1811-FAR
N	7/0.2mm	100m	WN-140-D	XF-1804-FAR

