

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1201088475](#)
Status: **Active**
Overview: Brad Industrial Ethernet Solutions
Description: Double-Ended RJ-45 Cordset, 4 Poles, Male (Straight) to Male (Straight), 24 AWG, Teal Shielded TPU Cable, 2.0m (6.56') Length, 6.50mm (.256") Diameter

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	120108
Connector End A	RJ-45 (standard)
Connector End B	RJ-45 (standard)
IP Rating	IP20
Material - Contact	Phosphor Bronze
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Industrial Ethernet
Region	America, Asia, Europe
Taxonomy	Circular Industrial Cordsets
Type	Double Ended
UPC	889056361163

Physical

Cable Diameter	6.50mm (.256")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Teal
Coupling Style	Push and Latch
Gender	Male-Male
Keyway	N/A
LED Indicator	No
Material - Cable Jacket	TPU
Material - Connector Body	TPU
Material - Coupling Nut	N/A
Material - Plating Mating	Gold
Net Weight	129.500/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-20° to +50°C
Wire Size AWG	24
Wire/Cable Type	Shielded TPU

Electrical


Current - Maximum per Contact	1.5A
Voltage - Maximum	30V

Material Info

Engineering Number	E66A06016M020
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	1201088967-000, SD-120108-081-001
---------------	-----------------------------------

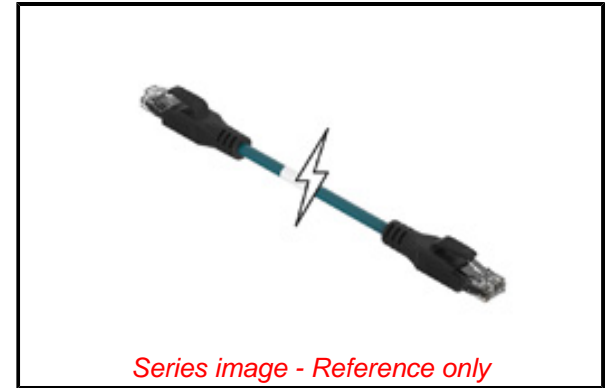

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[120108 Series](#)