

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300660069](#)
Status: **Active**
Overview: BradPower Cordsets and Receptacles
Description: BradPower A-Size (7/8"-M22) Receptacle, 4 Poles, Female, 1/2" - 14 NPT, 14/1 AWG, 0.5m (19.7") Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Receptacles
 Series [130066](#)
 IP Rating IP67
 Overview [BradPower Cordsets and Receptacles](#)
 Product Name BradPower A-Size
 Taxonomy Circular Industrial Connectors
 Type Single Ended (pigtail)
 UPC 78678856635

Physical

Coupling Type Internal Thread
 Gender Female
 Keyway Single
 Length 0.50m
 Material - Component Nickel-plated Zinc Die-Cast
 Mounting Thread Size 1/2" - 14 NPT
 Net Weight 111.000/g
 Orientation Straight
 Panel Mount Front
 Poles 4
 Temperature Range - Operating -20° to +105°C
 Wire Size AWG 14
 Wire/Cable Type UL 1015

Electrical


Current - Maximum per Contact 15.0A
 Voltage - Maximum 600V

Material Info

Engineering Number 1R4000A28M005G

Reference - Drawing Numbers

Sales Drawing SD-130066-076-001

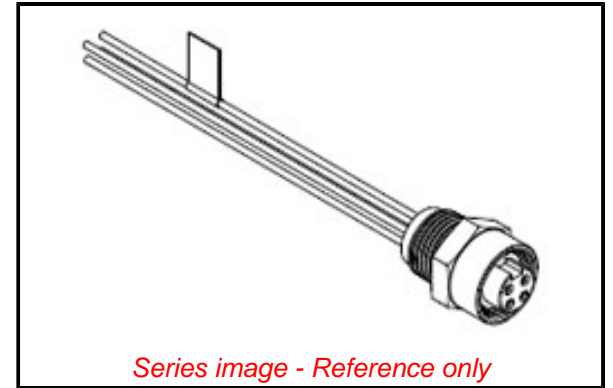

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per -
 D(2020)9139-DC (19
 Jan 2021)
 Silicic acid (H₂Si₂O₅),
 barium salt (1:1),
 lead-
 diethyl sulphate
 Acetamide, N-methyl-
 Dinoseb
 1-bromopropane
 furan
 Perfluorododecanoic
 acid
 Perfluoromyristic acid
 methoxyacetic acid
 1,2-diethoxyethane
 Perfluoro-n-
 undecanoic acid
 sodium
 peroxometaborate
 Pentacosafuorotridecanoic
 acid
 3-ethyl-2-methyl-2-
 (3-methylbutyl)-1,3-
 oxazolidi
 Hydrazine
 Hexabromocyclododecane
 (HBCDD)
 Trixylyl phosphate
 4-(1,1,3,3-
 tetramethylbutyl)phenol,
 ethoxylated
 Methylhexahydrophthalic
 anhydride
 Sodium perborate;
 perboric acid, sodium
 salt
 Cadmium-chloride

China RoHS

Dodecachloropentacyclo[12.2.1.16,9.02,13.05,10]o

Arsenic acid
(H₃AsO₄), triethyl
ester

Diarsenic-pentaoxide

Diarsenic-trioxide

5-tert-Butyl-2,4,6-
trinitro-m-xylene

2,4-Dinitrotoluene

1-Methyl-2-

pyrrolidone

formamide

4,4'-

bis(dimethylamino)benzophenone

N,N,N',N'-

Tetramethyl-4,4'-

methylenedianiline

1,2-bis(2-

methoxyethoxy)ethane

[4-[4,4'-

bis(dimethylamino)

benzhydrylidene]cycl

4,4'-

bis(dimethylamino)-4"-

(methylamino)trityl

Diboron-trioxide

[4-[[4-Anilino-1-

naphthyl]][4-

(dimethylamino)phen

α,α #Bis[4-

(dimethylamino)phenyl]-4

(phenylamino)

Lead

Cadmium-chloride

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

ZZCERT_CE -

CER_4000408918_00_000.pdf

Declaration of

Conformity

ZZCERT_UKCA

CER_4000410292_00_000.pdf

- Declaration of

Conformity

Search Parts in this Series

[130066 Series](#)

This document was generated on 09/27/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION