


MPP ARCA 3030

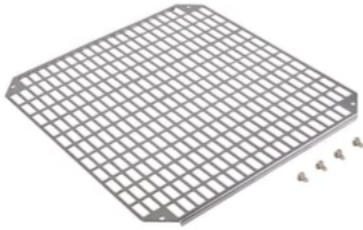

Sample image

Order symbol: MPP ARCA 3030

Product nbr: 8120752

Description : Mounting plate perforated (250x250x2 mm - 26x11 mm)

Remarks : Galvanized steel. for size 300x300x210

Including :

EAN: 6418074082732

El. number:

- Finland: 3423833
- Denmark:
- Sweden:

Dimensions:

	Length	Width	Height
mm:		250	250
inch:		9.84	9.84

Materials:

Material: _____

Base colour: _____

Cover colour: _____

Gasket material: _____

Temperatures:

Temperature °C (short term): _____

Temperature °C (continuous): _____

Temperature °F (short term): _____

Temperature °F (continuous): _____

Rating:

Ingress protection (EN 60529): _____

Impact Resistance (EN 62262): _____

Electrical insulation: _____ Not insulated

Halogen free (DIN/VDE 0472, Part 815): _____ 0

UV resistance: _____ -

Flammability Rating: _____

Glow Wire Test (IEC 695-2-1) °C: _____

NEMA Class _____

Certificates: _____