


# MPP ARCA 5050

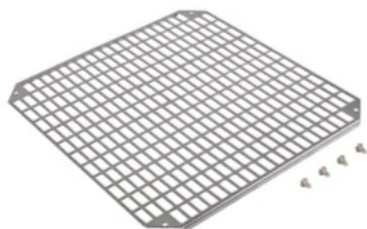

Sample image

**Order symbol:** MPP ARCA 5050

**Product nbr:** 8120750

**Description :** Mounting plate  
perforated (450x450x2 mm -  
26x11 mm)

**Remarks :** Galvanized steel. for size  
500x500x210

**Including :**

**EAN:** 6418074314727

**El. number:**

- Finland:
- Denmark:
- Sweden:

**Dimensions:**

	Length	Width	Height
mm:		450	450
inch:		17.72	17.72

**Materials:**

Material: \_\_\_\_\_

Base colour: \_\_\_\_\_

Cover colour: \_\_\_\_\_

Gasket material: \_\_\_\_\_

**Temperatures:**

Temperature °C (short term): \_\_\_\_\_

Temperature °C (continuous): \_\_\_\_\_

Temperature °F (short term): \_\_\_\_\_

Temperature °F (continuous): \_\_\_\_\_

**Rating:**

Ingress protection (EN 60529): \_\_\_\_\_

Impact Resistance (EN 62262): \_\_\_\_\_

Electrical insulation: \_\_\_\_\_ Not insulated

Halogen free (DIN/VDE 0472, Part 815): \_\_\_\_\_ 0

UV resistance: \_\_\_\_\_ -

Flammability Rating: \_\_\_\_\_

Glow Wire Test (IEC 695-2-1) °C: \_\_\_\_\_

NEMA Class \_\_\_\_\_

**Certificates:**