

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1201088451](#)  
**Status:** **Active**  
**Overview:** Brad Industrial Ethernet Solutions  
**Description:** Micro-Change (M12) to Standard RJ-45 Double-Ended Cordset, 4 Poles, Male (Straight) to Male RJ-45 (Straight), 24 AWG, Teal Shielded TPU Cat5e Cable, 2.0m (6.56') Length

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Cordsets
Series	<a href="#">120108</a>
Connector End A	Micro-Change (M12)
Connector End B	RJ-45 (standard)
IP Rating	IP20, IP67
Material - Contact	Brass, Phosphor Bronze
Overview	<a href="#">Brad Industrial Ethernet Solutions</a>
Performance Category	5e
Product Name	Micro-Change (M12), RJ45
Region	America, Asia, Europe
Taxonomy	Circular Industrial Cordsets
Type	Double Ended
UPC	889056360920

**Physical**

Cable Diameter	6.50mm (.256")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Teal
Coupling Style	Push and Latch, Threaded
Gender	Male-Male
Keyway	D-coded
LED Indicator	No
Material - Cable Jacket	TPU
Material - Connector Body	TPU
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	81.000/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-25° to +80°C
Wire Size AWG	24
Wire/Cable Type	Shielded TPU

**Electrical**


Current - Maximum per Contact	1.5A
Voltage - Maximum	30V

**Material Info**

Engineering Number	E16A06016M020
--------------------	---------------

**Reference - Drawing Numbers**

Sales Drawing	1201088450-000, SD-120108-084-001
---------------	-----------------------------------

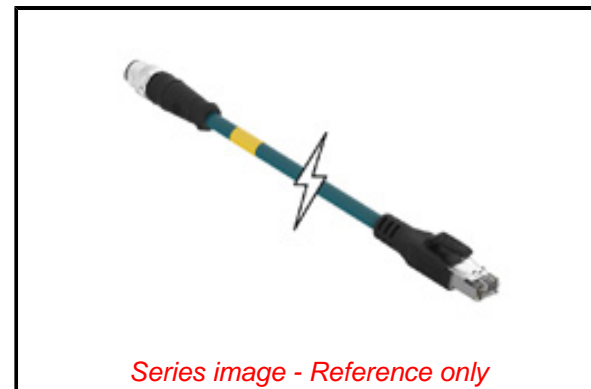

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - D(2022)4187-DC (10 June 2022)

Lead

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT\_CE -

Declaration of

Conformity

**China RoHS**

50 Image

Not Relevant

Not Contained

CER\_4000380981\_00\_000.pdf

**Search Parts in this Series**

120108 Series