


Coaxial Panel Connector 22_MM CX-50-0-4/111_O

Description

Straight bulkhead receptacle jack

Interface standards
SUHNER-MM CX

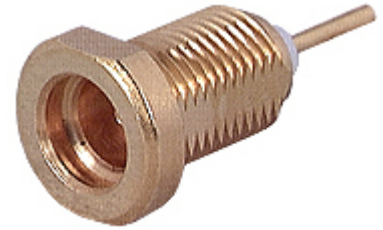

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	6 GHz

Mechanical Data

Chassis torque	0.4 Nm
Number of matings	500
Weight	0.0003 kg

Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Brass	Gold Plating (without Nickel underplating)
Body	Brass	Gold Plating (without Nickel underplating)
Insulator	PFA / PTFE	

Related Documents

Outline drawing	DOU-00010462
Catalogue drawing	DCA-00010464
Mounting hole	DOU-00009144

Ordering Information

Bulk 100 pcs package	22_MM CX-50-0-4/111_OH
----------------------	------------------------