


Coaxial PCB Connector 82_MBX-50-0-3/111_N

Description

Straight PCB jack

Interface Standards
HUBER+SUHNER MBX

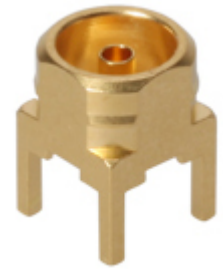

Technical Data

Electrical Data

Impedance 50 Ω
Interface frequency max. 6 GHz

Mechanical Data

Board mounting type through holes
Weight 0.000725 kg

Environmental Data

Operating temperature -55 °C to 155 °C
2011/65/EU (RoHS - including
2015/863 and 2017/2102) compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	SUCOPRO Plating
Outer contact	Brass	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	LCP (Liquid crystal polymer)	

Related Documents

Outline drawing DOU-00144733
Catalogue drawing DCA-00161423
Mounting hole DPA-00144881

Ordering Information

Tape and Reel package 82_MBX-50-0-3/111_NM
Bulk 100 pcs package 82_MBX-50-0-3/111_NH
Single package 82_MBX-50-0-3/111_NE

Remarks

PCB connector with stand-offs