


## Coaxial Cable Connector 16\_MCX-75-2-5/133\_N

### Description

Right angle cable plug

Interface standards  
SUHNER-MCX75

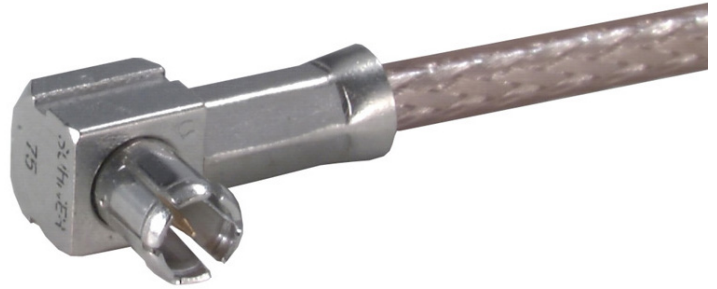

### Technical Data

#### Electrical Data

Impedance	75 Ω		
Interface frequency max.	6 GHz		
Frequency range	DC to 1 GHz	1 to 2.5 GHz	2.5 to 6 GHz

#### Mechanical Data

Centre contact	soldered
Outer contact	crimped
Weight	0.0012 kg

#### Environmental Data

Operating temperature	-55 °C to 155 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

#### Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	SUCOPLATE (R) Plating
Body	Brass	SUCOPLATE (R) Plating
Insulator	PFA / PTFE	
Crimp ferrule	Copper	SUCOPLATE (R) Plating

### Related Documents

Outline drawing	DOU-00007524
Catalogue drawing	DOU-00007526
Assembly instruction	DOC-0000179474

### Ordering Information

Bulk 100 pcs package	16_MCX-75-2-5/133_NH
Single package	16_MCX-75-2-5/133_NE

### Additional Information

Suitable cables	ENVIROFLEX_179, RG_179_B/U, RG_187_A/U
-----------------	--