


## Coaxial Cable Connector 16\_MCX-50-2-104/111\_NH-1

### Description

Right angle cable plug

Interface standards

IEC 60169-36\_CECC 22220

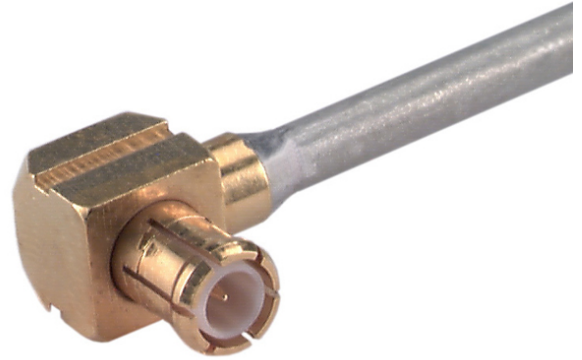

### Technical Data

#### Electrical Data

Impedance	50 $\Omega$		
Interface frequency max.	6 GHz		
Frequency range	DC to 2.5 GHz	2.5 to 4 GHz	4 to 6 GHz
Return loss	30 dB	25 dB	22 dB

#### Mechanical Data

Centre contact	soldered
Outer contact	soldered
Weight	0.0008 kg

#### Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

#### Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	PFA / PTFE	

### Related Documents

Outline drawing	DOU-00006447
Catalogue drawing	DOU-00006449
Assembly instruction	DOC-0000180001

### Ordering Information

Bulk 100 pcs package	16_MCX-50-2-104/111_NH-1
----------------------	--------------------------

### Additional Information

Suitable cables	EZ_86_TP_M17
-----------------	--------------