


Coaxial Cable Connector 16_MCX-50-2-11/111_N_-1

Description

Right angle cable plug

Interface standards

IEC 60169-36_CECC 22220

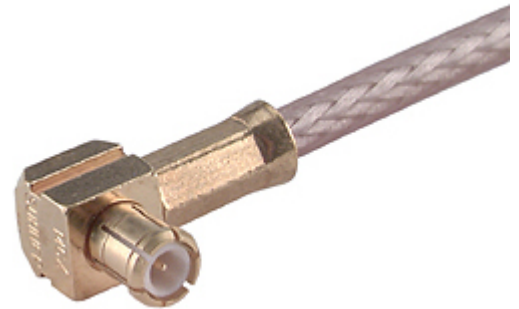

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	6 GHz

Mechanical Data

Centre contact	soldered
Outer contact	crimped
Weight	0.0011 kg

Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Body	Brass	SUCOPRO Plating
Insulator	PFA / PTFE	
Crimp ferrule	Copper	Gold Plating (without Nickel underplating)

Related Documents

Outline drawing	DOU-00006014
Catalogue drawing	DOU-00006016
Assembly instruction	DOC-0000179229

Ordering Information

Bulk 100 pcs package	16_MCX-50-2-11/111_NH-1
----------------------	-------------------------

Additional Information

Suitable cables	K_02252_D, ENVIROFLEX_316_D, G_02232_D
-----------------	--