

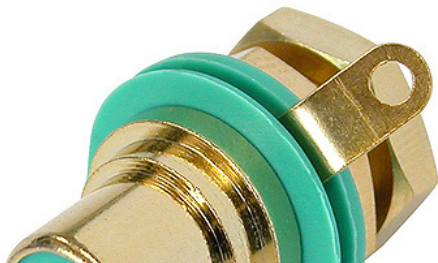
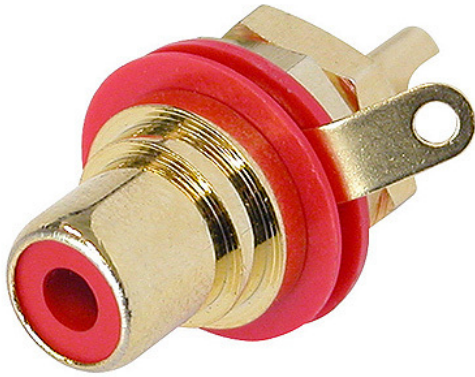


NYS367

Phono jack, gold plated contacts

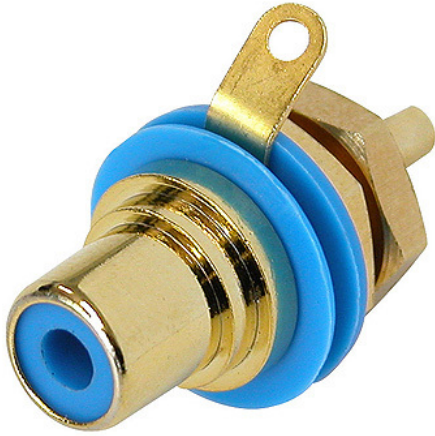

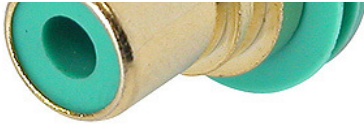

Article Variations

Article Name	Details	Packaging
NYS367-0	Black color coding	
NYS367-2	Red color coding	
NYS367-4	Yellow color coding	
NYS367-5	Green color coding	
NYS367-6	Blue color coding	
NYS367-9	White color coding	

Technical Information

Product

Title	NYS367
Connection Type	Phono ("RCA/Cinch")

Electrical

Contact Resistance	≤10 mΩ
Insulation Resistance	>2000 MΩ(Initial)
Rated Voltage	0.5 VAC

Mechanical

Insertion and Withdrawal Force	5-20N
Lifetime	>5000 Mating Cycles

Material

Housing	Brass
Nut	Brass
Washer	PA+30%GF
Lug	Brass
Washer	PA+30%GF
Pin	Brass
Housing	Gold
Nut	Gold
Lug	Gold
Pin	Gold